


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [5051480408](#)  
**Status:** **Active**  
**Overview:** Flexi-Latch Right-Angle FPC-to-Board Connector System  
**Description:** 2.00mm Pitch Flexi-Latch FPC-to-Board Plug Jacket, 4 Circuits

**Documents:**

<a href="#">3D Model (PDF)</a>	<a href="#">Application Specification 5051480000-A00 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Packaging Specification 5051489200-200 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification 5051470000-000 (PDF)</a>	

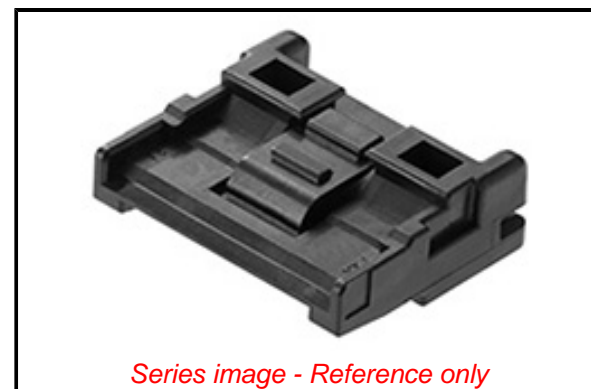

*Series image - Reference only*

**Agency Certification**

UL E29179

**General**

Product Family	Accessories
Series	<a href="#">505148</a>
Component Type	Jacket
Overview	<a href="#">Flexi-Latch Right-Angle FPC-to-Board Connector System</a>
Product Name	Flexi-Latch
UPC	889056420082

**Physical**

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Gender	Plug
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	340.388/mg
Packaging Type	Bag
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +125°C

**Electrical**

Current - Maximum per Contact 2.0A

**Material Info**

**Reference - Drawing Numbers**

Application Specification	5051480000-A00
Packaging Specification	5051489200-200
Product Specification	5051470000-000
Sales Drawing	5051480000-000

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[505148 Series](#)

**Use With**

Flexi-Latch FPC-to-Board Connector  
[5051470490](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[505148-0408](#)