

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **5056060800**
Status: **Active**
Overview: CP Wire-to-Board and Wire-to-Wire Connector Systems
Description: CP-3.3 Plug Housing, 3.30mm Pitch, Dual Row, Polarized, Positive Inertia Lock, 8 Circuits, Natural

Documents:

3D Model	Application Specification 5056050000-A01 (PDF)
Drawing (PDF)	Packaging Specification 5056069200-200 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification 5056050000-000 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 5056050000-A00 (PDF)	

Agency Certification

UL E29179

General

Product Family	Crimp Housings
Series	505606
Application	Signal, Wire-to-Wire
Overview	CP Wire-to-Board and Wire-to-Wire Connector Systems
Product Name	CP-3.3
UPC	889056804462


Physical

Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	3349.000/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Pitch - Termination Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	5056050000-A00, 5056050000-A01
Packaging Specification	5056069200-200
Product Specification	5056050000-000
Sales Drawing	5056060000-000

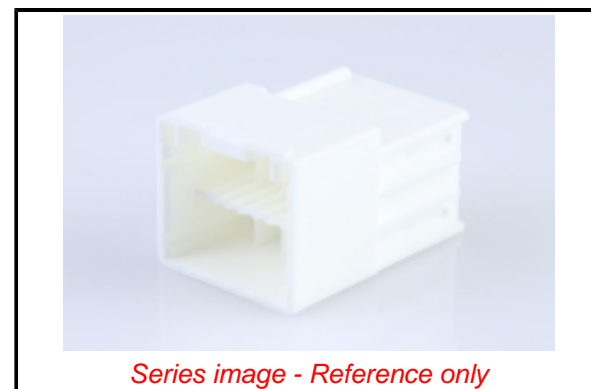

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[505606](#) Series

Mates With

Receptacle Housing [5056050800](#)

Use With

Terminal Retainer [504695](#) . Plug Crimp
Terminal [50398](#) , [505608](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[505606-0800](#)