


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2005020122](#)
Status: **Active**
Overview: [stAK50h Connection System](#)
Description: [stAK50h Right-Angle Hybrid Header, 12 Circuits, Key 2, Green, Tube](#)

Documents:

3D Model	Product Specification 2005060001-PS-000 (PDF)
3D Model (PDF)	Application Specification 2005060000-AS-000 (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification 1600140001-000 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 1600140002-PS-000 (PDF)	

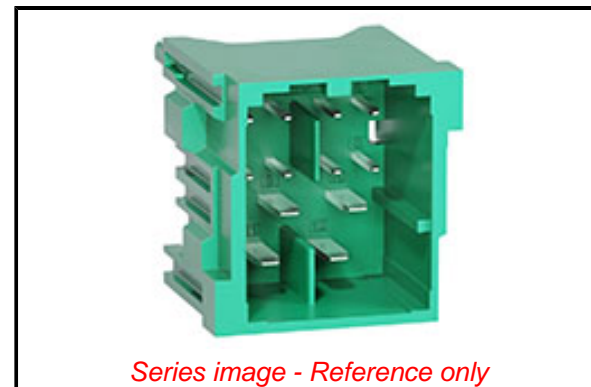

General

Product Family	PCB Headers
Series	200502
Application	Automotive, Power, Signal, Wire-to-Board
Overview	stAK50h Connection System
Product Name	stAK50h
UPC	889056679626

Physical

Breakaway	No
Circuits (Loaded)	12
Circuits (maximum)	12
Color - Resin	Green
Durability (mating cycles max)	10
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	SPS
Net Weight	10.020/g
Number of Rows	4
Orientation	Right Angle
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Tube
Pitch - Mating Interface	2.00mm, 4.00mm, 5.20mm, 7.20mm
Pitch - Termination Interface	2.00mm, 3.20mm, 4.00mm, 5.20mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Yes
Stackable	Yes
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C LV-214, -40° to +85°C GMW3191
Termination Interface: Style	June2012 Through Hole

Electrical

Current - Maximum per Contact	12.0A, 30.0A
Voltage - Maximum	14V DC

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[200502 Series](#)

Mates With

[stAK50h Hybrid Receptacle 1600260002](#)

Material Info

Reference - Drawing Numbers

Application Specification

Product Specification

Sales Drawing

2005060000-AS-000

1600140001-000, 1600140002-PS-000, 2005060001-
PS-000

2005021120SD-000

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[200502-0122](#)