

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395140112](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 3.81mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Standard Imprinting, 12 Circuits

Documents:

Drawing (PDF)	Packaging Specification PK-39514-001-001 (PDF)
Product Specification PS-39500-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-39500-001-001 (PDF)	

Agency Certification

UL	E48521
----	--------

General

Product Family	Terminal Blocks
Series	39514
Application	N/A
Comments	with Standard Imprinting
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350689182

Physical

Circuits (Loaded)	12
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	16, 18, 20, 22, 24
Wire Size mm²	0.20-1.31


Electrical

Current - Maximum per Contact	8.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-39500-001-001, PK-39514-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39514-001

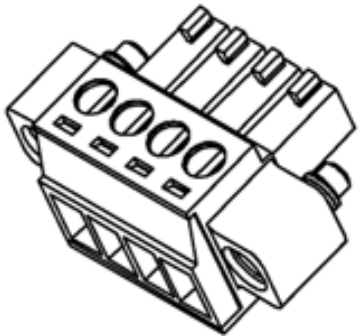

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39514](#) Series

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39515](#) Vertical PCB Header with Threaded Retention Inserts, [39516](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39514-0112](#)