

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0533091070](#)
Status: **Active**
Overview: [SlimStack Board-to-Board/Board-to-FPC Connectors](#)
Description: SlimStack Board-to-Board Connector, 0.80mm Pitch, Plug, 5.65 or 6.65mm Mated Height, 10 Circuits, Right-Angle, without Boss

Documents:

| | |
|--|---|
| 3D Model (PDF) | Packaging Specification SPK-53309-001-001 (PDF) |
| Drawing (PDF) | Datasheet (PDF) |
| 3D Model | Product Guide (PDF) |
| Product Specification PS-52465-014-001 (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-52588-031-001 (PDF) | Reference Guide (PDF) |

General


| | |
|----------------|--|
| Product Family | PCB Headers |
| Series | 53309 |
| Application | Board-to-Board, Signal |
| Overview | SlimStack Board-to-Board/Board-to-FPC Connectors |
| Product Name | SlimStack |
| Series Name | 0.8 and above |
| UPC | 822348124237 |

Physical

| | |
|--------------------------------|--------------------------------|
| Breakaway | No |
| Circuits (Loaded) | 10 |
| Circuits (maximum) | 10 |
| Color - Resin | Natural |
| Durability (mating cycles max) | 30 |
| First Mate / Last Break | No |
| Glow-Wire Capable | No |
| Guide to Mating Part | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Mated Height | 5.65mm, 6.65mm |
| Mated Width | 4.70mm, 7.20mm |
| Material - Metal | Phosphor Bronze |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Material - Resin | High Temperature Thermoplastic |
| Net Weight | 199.640/mg |
| Number of Rows | 2 |
| Orientation | Right Angle |
| PC Tail Length | 0.40mm, 0.50mm |
| PCB Locator | No |
| PCB Retention | None |
| Packaging Type | Embossed Tape on Reel |
| Pitch - Mating Interface | 0.80mm |
| Plating min - Mating | 1.016µm |
| Plating min - Termination | 1.016µm |
| Polarized to PCB | No |
| Shrouded | Fully |
| Temperature Range - Operating | -40° to +105°C |
| Termination Interface: Style | Surface Mount |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum | 50V |

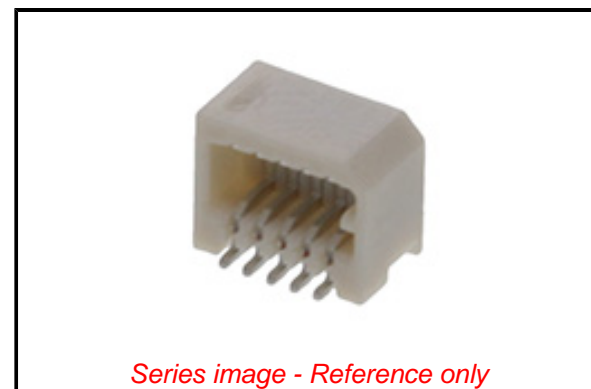

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[53309](#) Series

Mates With

[52465](#) , [52588](#) Board-to-Board Receptacle

Material Info

Reference - Drawing Numbers

Packaging Specification

Product Specification

Sales Drawing

SPK-53309-001-001

PS-52465-014-001, PS-52588-031-001

533090000-000, 533091000-000

This document was generated on 12/14/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53309-1070](#)