

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638119200](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for CP 0.635mm Female Terminals for CMC connector, 0.50-0.75mm² Wire

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207129
Comments	Field Repair, See Tooling Specification (PDF) Above. Type: 7
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Tool Type	Hand Crimp Tool
UPC	822350980494
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


Physical

Net Weight 0.001/kg

Material Info

Reference - Drawing Numbers

Application Tooling Documents
ATS-638119200-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

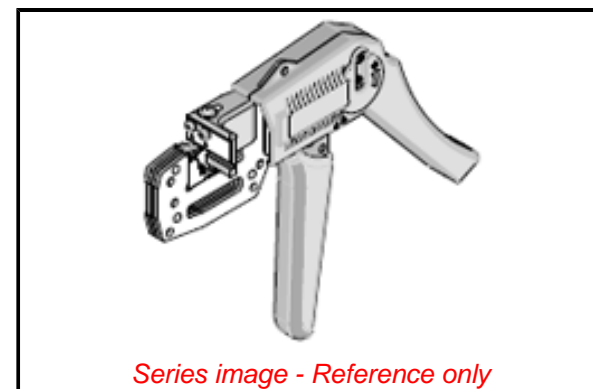

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

[207129 Series](#)

Use With

Loose Piece Terminals

Application Tooling | [FAQ](#)

Description	Product #
0.635mm CMC CP Female Terminal, Tin Plated, for Square Pins, Wire Size 0.75mm ²	643221029
0.635mm CMC CP Female Terminal, Tin Plated, for Square Pins, Wire Size 0.5mm ²	643221039
0.635mm CMC CP Female Terminal, Tin Plated, Selective 1.27µm Gold in Contact Area, for	643221219

Square 0.6mm x
0.6mm Pins, Wire
Size 0.75mm²
0.635mm CMC CP [643221239](#)
Female Terminal,
Tin Plated, Selective
1.27μm Gold in
Contact Area, for
Square 0.6mm x
0.6mm Pins, Wire
Size 0.5mm²
0.635mm CMC CP [643221339](#)
Female Terminal,
HP Version, Tin
Plated, Selective
1.27μm Gold in
Contact Area, for
Square 0.60mm x
0.60mm Pins, Wire
Size 0.75mm²
0.635mm CMC CP [643221359](#)
Female Terminal,
HP VERSION, Tin
Plated, Selective
1.27μm Gold in
Contact Area, for
Square 0.6mm x
0.6mm Pins, Wire
Size 0.5mm²

This document was generated on 11/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63811-9200](#)