

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5009130402](#)
Status: **Active**
Overview: [SlimStack Board-to-Board/Board-to-FPC Connectors](#)
Description: SlimStack Board-to-Board Receptacle, 0.40mm Pitch, J-Bend Series, 1.80 or 2.30mm Mated Height, 4.20mm Mated Width, 40 Circuits

Documents:

3D Model (PDF)	Datasheet (PDF)
3D Model	Product Guide (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-500913-001-001 (PDF)	Reference Guide (PDF)
Packaging Specification SPK-500913-001-001 (PDF)	

General

Product Family	PCB Receptacles
Series	500913
Application	Board-to-Board, Signal
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.4, J-Bend
UPC	822348544073

Physical


Circuits (Loaded)	40
Circuits (maximum)	40
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	Yes
Mated Height	1.80mm, 2.30mm
Mated Width	4.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Net Weight	96.831/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Plating min - Mating	0.254µm
Plating min - Termination	0.051µm
Polarized to Mating Part	No
Polarized to PCB	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

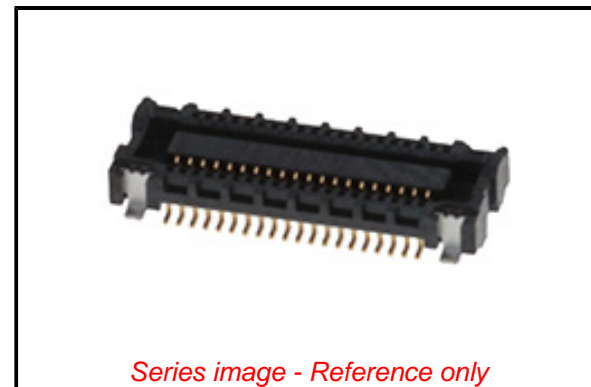

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[500913 Series](#)

Mates With

[SlimStack J-Bend Plug 55909](#) , [501745](#)

Packaging Specification
Product Specification
Sales Drawing

SPK-500913-001-001
PS-500913-001-001
SD-500913-001-001, SD-500913-002-001

This document was generated on 02/07/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[500913-0402](#)