

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390127](#)
Status: **Active**
Overview: Brad Mini-Change Connectors
Description: DeviceNet D-Net Open with Screws Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130039](#)
 Connector End A D-Net Open
 Connector End B Pigtail
 IP Rating IP20
 Material - Contact Brass
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet
 Region Europe
 Type Single Ended
 UPC 78678848190

Physical

Cable Diameter N/A
 Cable Length 1.0m (3.28')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body TPE
 Material - Coupling Nut N/A
 Material - Plating Mating Gold
 Orientation Straight to Pigtail
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 22
 Wire/Cable Type E152210

Electrical


Current - Maximum per Contact 10.0A
 Voltage - Maximum 300V DC

Material Info

Engineering Number DND40-M010

Reference - Drawing Numbers

Sales Drawing SD-130039-031

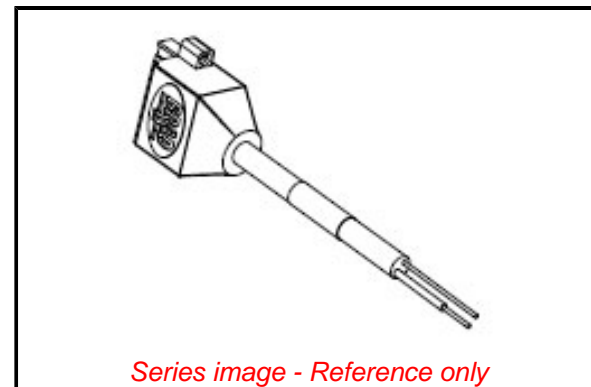

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130039 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300390127](#)