


BU-P4773-@

(Miniature Insulated Pin Jack with Wrapped Wire Terminal)

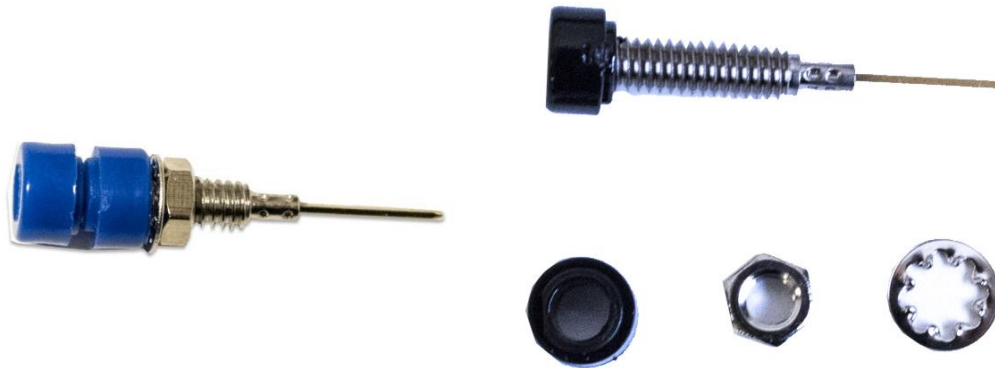

- The BU-P4773 is a Tip Jack Connector Miniature with a Wire Wrap
- Accepts 0.08" (2.032mm) dia. Pin
- Maximum panel thickness it accepts is 0.25" (6.35mm)
- Square pin is 0.45" (11.43mm) long and 0.025" (0.635mm) thick
- Jack is 0.89" (22.61mm) long and 0.31" (7.87mm) in diameter\
 - Pole Threads: 8-32
- Material:
 - Insulator – Polycarbonate
 - Pin Jack Body – Nickel plated Brass
 - Spring – Gold plated Beryllium Copper
 - Wrapped Wire Terminal – Gold plated Phosphor Bronze
- Rating:
 - Operating Temperature - +115°C Max
 - Operating Voltage – 1500 VDC
 - Current – 3 Amps
- Color: The "@" in the model number indicates color.
Available colors are: -0 Black, -2 Red, -6 Blue, -9 White
- RoHS 2 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[BU-P4773-0](#)