


### C4A05UXXX

(M12 Cordset, 4 Position, 22 AWG Shielded, Male Straight to Free End)

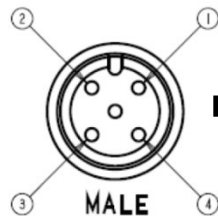

Pin Out		
End 1	Color	End 2
1	Brown	Free End
2	White	
3	Blue	
4	Black	

- 
- Mueller's C4A05UXXX is an M12 4-pin single ended, shielded instrumentation cable with a straight male connector on one end and free at the other.
- Keyway – A Coding
- Utilizes a 4-conductor 22 AWG PVC-insulated, shielded cable.
- Ratings:
  - Current: 4 A
  - Voltage: 250 V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement. Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C4A05M010](#)