



C4AC10UXXX

(M12 Cordset, 4 Position, 22 AWG Unshielded, Male Straight to Female Straight)

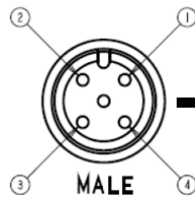

Pin Out		
End 1	Color	End 2
1	Brown	1
2	White	2
3	Blue	3
4	Black	4

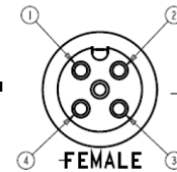

- Mueller's C4AC10UXXX is an M12 4-pin double ended, unshielded instrumentation cable with a straight male connector on one end and a straight female connector on the other.
- Keyway – A Coding
- Utilizes a 4-conductor 22 AWG PVC-insulated, unshielded cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C4AC10M001](#) [C4AC10M003](#) [C4AC10M006](#)