



### C5AD11UXXX

(M12 Cordset, 5 Position, 22 AWG Unshielded, Male Straight to Female Right Angle)

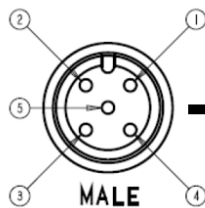

Pin Out		
End 1	Color	End 2
1	Brown	1
2	White	2
3	Blue	3
4	Black	4
5	Gray	5

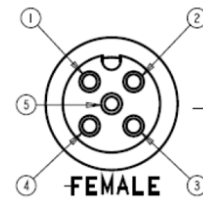

- Mueller's C5AD11UXXX is an M12 5-pin double ended, unshielded instrumentation cable with a straight male connector on one end and a right-angle female at the other.
- Keyway – A Coding
- Utilizes a 5-conductor 22 AWG PVC-insulated, unshielded cable.
- Ratings:
  - Current: 4 A
  - Voltage: 250 V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C5AD11M002](#)