



3225R

Surface Mount Inductors



Features and Benefits

- RoHS Compliant

Parameters

Current Rating at 90°C Ambient 35°C Rise

Operating Temperature Range -55°C to +125°C

Part Storage Temperature Range -65°C to +125°C

Maximum Power Dissipation at 90°C Ambient 0.217 W


Optional Tolerances K = 10%, J = 5%

Weight/Mass 0.1 Grams Maximum

Core Material / Termination Finish

Ferrite / Sn Finish

Dimensions

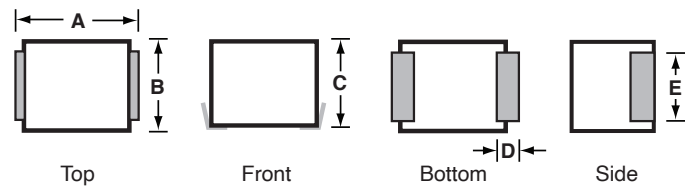

	Inches	Millimeters
A	0.118 to 0.134	3.00 to 3.40
B	0.090 to 0.106	2.30 to 2.70
C	0.079 to 0.095	2.00 to 2.40
D	0.016 (TYP.)	0.40 (TYP.)
E	0.071 to 0.079	1.80 to 2.00

Dimensions A and C are over terminals

Suggested Land Pattern

	Inches	Millimeters
X	0.094	2.40
Y	0.039	1.00
Z	0.078	2.00

Country of Origin: Taiwan

API Delevan®

270 Quaker Rd., East Aurora NY 14052 • Phone 716-652-3600 • E-mail: apisales@delevan.com • www.delevan.com



3225R

Surface Mount Inductors



Electrical Characteristics

Part Number Prefix	L (uH)	Inductor Tolerance (%)	Q (Min.)	L & Q Test Frequency (MHz)	SRF Min (MHz)	DCR Max (Ohms)	Current Rating (mA)
3225R-102	1.0	10	25	7.9	120	0.70	515
3225R-122	1.2	10	25	7.9	100	0.75	497
3225R-152	1.5	10	25	7.9	85	0.85	467
3225R-182	1.8	10	25	7.9	75	0.90	454
3225R-222	2.2	5	25	7.9	70	1.00	431
3225R-272	2.7	5	25	7.9	65	1.10	411
3225R-332	3.3	5	25	7.9	58	1.20	393
3225R-392	3.9	5	25	7.9	50	1.30	378
3225R-472	4.7	5	25	7.9	45	1.50	352
3225R-562	5.6	5	25	7.9	42	1.60	341
3225R-682	6.8	5	25	7.9	40	1.80	321
3225R-822	8.2	5	25	7.9	35	2.00	305
3225R-103	10.0	5	25	7.9	30	2.10	297
3225R-123	12.0	5	25	2.5	28	2.50	272
3225R-153	15.0	5	25	2.5	25	2.80	257
3225R-183	18.0	5	25	2.5	23	3.30	237
3225R-223	22.0	5	25	2.5	20	3.70	224
3225R-273	27.0	5	25	2.5	18	5.00	193
3225R-333	33.0	5	25	2.5	15	5.60	182
3225R-393	39.0	5	25	2.5	14	6.40	170
3225R-473	47.0	5	25	2.5	13	7.00	163
3225R-563	56.0	5	25	2.5	11	8.00	152
3225R-683	68.0	5	25	2.5	10	9.00	144
3225R-823	82.0	5	25	2.5	9	10.00	136
3225R-104	100.0	5	25	2.5	8	13.00	120

Self Resonant Frequency (SRF) values are calculated and for reference only

Country of Origin: Taiwan

API Delevan®

270 Quaker Rd., East Aurora NY 14052 • Phone 716-652-3600 • E-mail: apisales@delevan.com • www.delevan.com



3225R

Surface Mount Inductors



Tape and Reel Specifications

Reel Size: 7" (178mm)

Tape Width: 8mm

Parts Per Reel: 2000 Pieces Maximum

Individual Part Marking

Three Digit Dash Number

Part Marking Example: 182

How To Order

3225R

—

182

J

Inductor Series

Inductance
3 digit dash no.

Tolerance
J = 5%
K = 10%

Country of Origin: Taiwan

API Delevan®

270 Quaker Rd., East Aurora NY 14052 • Phone 716-652-3600 • E-mail: apisales@delevan.com • www.delevan.com

All product specifications and data contained herein are subject to change without notice to improve reliability, function, performance, design or otherwise. This product may not be used in medical or high risk applications without prior API Delevan consent.

10/25/2019

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delevan:](#)

[3225R-182J](#) [3225R-104J](#) [3225R-103J](#)