

# LQG15WZ15NG02#

“#” indicates a package specification code.


Size Code 1005 (0402) in mm (in inch), Multilayer Type, High Q, Automotive available (Infotainment)



< List of part numbers with package codes >

LQG15WZ15NG02B      LQG15WZ15NG02D      LQG15WZ15NG02J

## Appearance & Shape

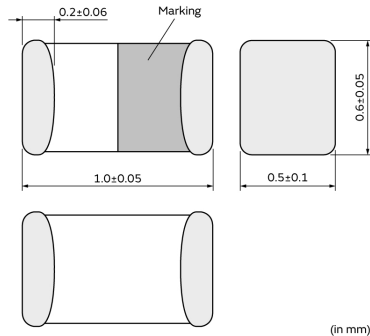

## References

| Packaging | Specifications   | Standard Packing Quantity |
|-----------|------------------|---------------------------|
| B         | Bulk(Bag)        | 100                       |
| D         | 180mm Paper Tape | 10000                     |
| J         | 330mm Paper Tape | 40000                     |

| Mass (typ.) |        |
|-------------|--------|
| 1 piece     | 0.001g |

### Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# LQG15WZ15NG02#

“#” indicates a package specification code.



## Specifications

|  |                |
|--|----------------|
| L size   | 1.0±0.05mm     |
| W size   | 0.6±0.05mm     |
| T size   | 0.5±0.1mm      |
| Size code inch (mm)  | 0402 (1005)    |
| Inductance   | 15nH±2%        |
| Inductance Test Frequency  | 100MHz         |
| Rated current (Itemp)<br>(Based on Temperature rise)                     | 400mA          |
| Max. of DC resistance  | 0.28Ω          |
| Q(min.)  | 23             |
| Q Test Frequency   | 250MHz         |
| Self resonance frequency<br>(min.)                                       | 2300MHz        |
| Operating Temperature<br>Range(Self-temperature rise<br>is not included) | -55°C to 125°C |
| Series   | LQG15WZ_02     |

### Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.


# LQG15WZ15NG02#

“#” indicates a package specification code.




## Characteristic Data


The charts below may show another part number which shares its characteristics.

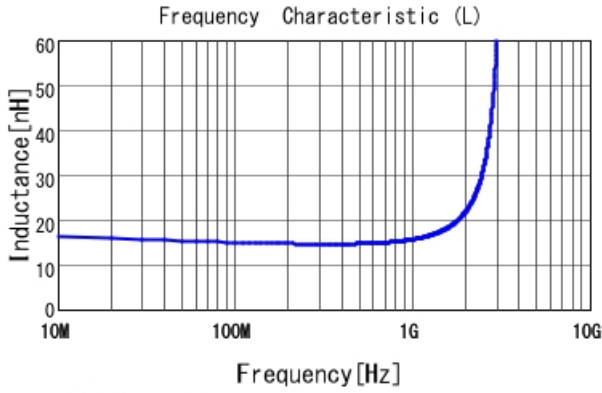

LQG15WZ15NG02 L

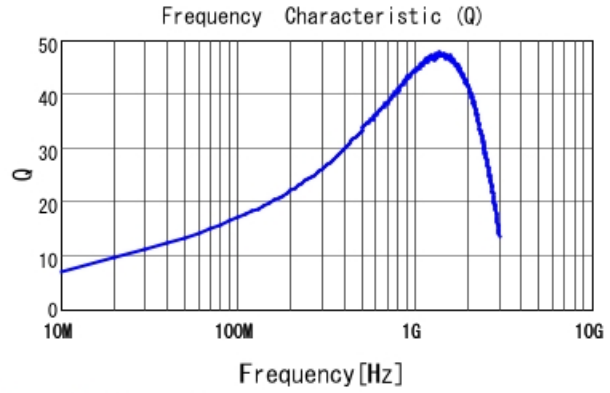

LQG15WZ15NG02 Q

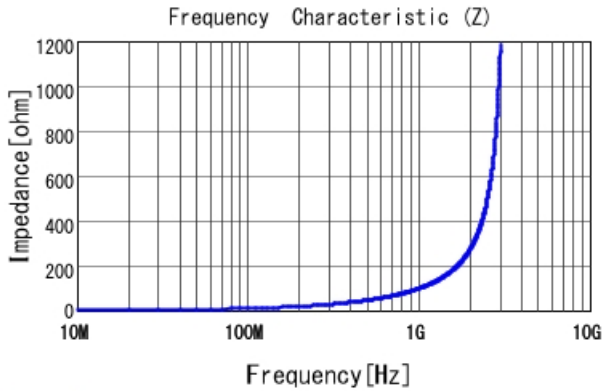

LQG15WZ15NG02 |Z|

### Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications.  
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[LQG15WZ15NG02D](#)