

# KYNAR® WIRE

## KYNAR® Insulated, Silver Plated Copper Conductor

Ideally suited for wire wrapping and many other applications. The Kynar insulation provides a flexible yet abrasion resistant wire and the conductor is made from silver plated OFHC (Oxygen Free High Conductivity) copper.

WIRE SIZE		INSULATION DIA.		ROLL SIZE		BLUE	YELLOW	WHITE	BLACK	RED	GREEN
AWG	mm	In.	mm	Feet	Meters						
24	0.50	.030	0.76	100	30.4	R24B-0100	R24Y-0100	R24W-0100	R24BLK-0100	R24R-0100	
26	0.40	.027	0.69	100	30.4	R26B-0100	R26Y-0100	R26W-0100	R26BLK-0100	R26R-0100	
28	0.32	.024	0.60	100	30.4	R28B-0100	R28Y-0100	R28W-0100	R28BLK-0100	R28R-0100	
30	0.25	.020	0.50	100	30.4	R30B-0100	R30Y-0100	R30W-0100	R30BLK-0100	R30R-0100	R30G-0100
				1000	304.4	R30B-1000	R30Y-1000	R30W-1000	R30BLK-1000	R30R-1000	R30G-1000




## Pre-Cut & Pre-Stripped Wire Wrapping Wire

30 AWG (0.25mm) Pre-Cut/Pre-Stripped Wire 50 Pieces/Pkg.

- 50 pieces per package
- Kynar® insulated
- Silver plated copper conductor
- UL listed
- 1" of stripped wire on either end
- Add 2" to the insulation length (see chart below) for total length of wire

INSULATION LENGTH		BLUE	YELLOW	WHITE	RED
In.	mm				
1	25	30-B-50-010	30-Y-50-010	30-W-50-010	30-R-50-010
2	51	30-B-50-020	30-Y-50-020	30-W-50-020	30-R-50-020
3	76	30-B-50-030	30-Y-50-030	30-W-50-030	30-R-50-030
5	127	30-B-50-050	30-Y-50-050	30-W-50-050	30-R-50-050



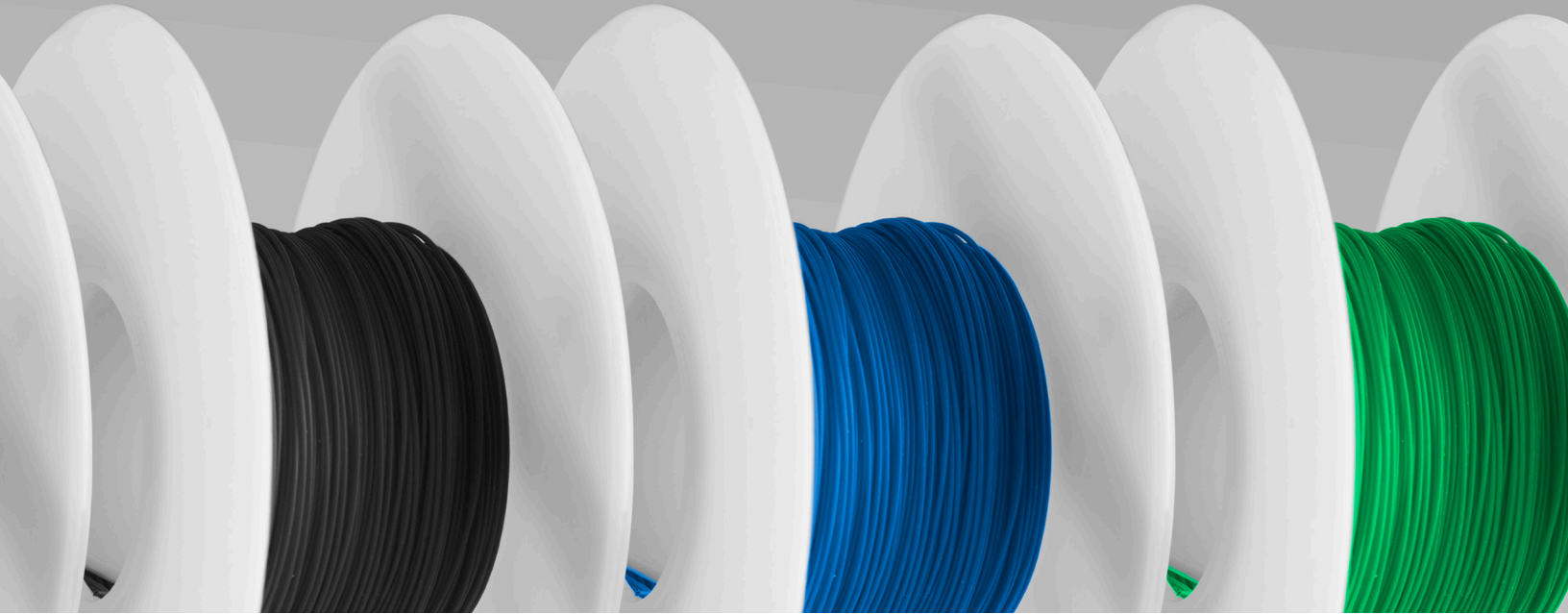

### KSW Wire Wrapping Wire Rolls for Cut/Strip/Wrap Applications

Low strip force Kynar® insulated silver plated copper conductor wire is further processed to provide a low strip force for use with CSW bits and sleeves. Ideally suited for wire wrapping and many other applications. The Kynar insulation provides a flexible yet abrasion resistant wire and the conductor is made from silver plated OFHC (Oxygen Free High Conductivity) copper.

WIRE SIZE		INSULATION DIA.		ROLL SIZE		BLUE	YELLOW	WHITE	BLACK	RED	GREEN
AWG	mm	In.	mm	Feet	Meters						
24	0.50	.030	0.76	100	30.4	KSW24B-0100	KSW24Y-0100	KSW24W-0100	KSW24BLK-0100	KSW24R-0100	
26	0.40	.027	0.69	100	30.4	KSW26B-0100	KSW26Y-0100	KSW26W-0100	KSW26BLK-0100	KSW26R-0100	
28	0.32	.024	0.60	100	30.4	KSW28B-0100	KSW28Y-0100	KSW28W-0100	KSW28BLK-0100	KSW28R-0100	
30	0.25	.020	0.50	100	30.4	KSW30B-0100	KSW30Y-0100	KSW30W-0100	KSW30BLK-0100	KSW30R-0100	KSW30G-0100
				1000	304.4	KSW30B-1000	KSW30Y-1000	KSW30W-1000	KSW30BLK-1000	KSW30R-1000	KSW30G-1000



### Wire Dispenser - WD-30 Series

- 50 ft. (15.2m) roll of 30 AWG (0.25mm) Kynar® wire-wrapping wire
- Built-in plunger cuts wire to desired length
- Built-in stripper strips 1" (25.4mm) of insulation
- Refillable

JONARD P/N	DESCRIPTION	REPLACEMENT ROLL OF WIRE
WD-30-B	Dispenser with 50' of Blue wire	R-30B-0050
WD-30-Y	Dispenser with 50' of Yellow wire	R-30Y-0050
WD-30-W	Dispenser with 50' of White wire	R-30W-0050
WD-30-R	Dispenser with 50' of Red wire	R-30R-0050
WD-30-TRI	Dispenser with 50' of Blue, White and Red wire	R-30-TRI





# KYNAR® WIRE BOXES

## KYNAR® Wire & Dispenser Box, 5 Color Set

The Wire Dispenser Box makes organizing and storing your wires a breeze. These kits include a dispenser box, five color spools of KYNAR® wire, and a **FREE JIC-2030!**

JONARD P/N	DISPENSER INCLUDES				TOTAL ROLL SIZE		INSULATION DIA.		WIRE SIZE		UPC #
	YELLOW	WHITE	BLACK	RED	Feet	Meters	In.	mm	AWG	mm	
<b>R24-5100</b>	R24Y-0100	R24W-0100	R24BLK-0100	R24R-0100	500	152.4	.030	0.76	24	0.50	810053359587
<b>R26-5100</b>	R26Y-0100	R26W-0100	R26BLK-0100	R26R-0100	500	152.4	.027	0.69	26	0.40	810053359594
<b>R28-5100</b>	R28Y-0100	R28W-0100	R28BLK-0100	R28R-0100	500	152.4	.024	0.60	28	0.32	810053359600
<b>R30-5100</b>	R30Y-0100	R30W-0100	R30BLK-0100	R30R-0100	500	152.4	.020	0.50	30	0.25	810053350355
<b>R30-51000</b>	R30Y-1000	R30W-1000	R30BLK-1000	R30R-1000	5000	1524	.020	0.50	30	0.25	810053359624



**MADE FOR LIFE**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Jonard Tools:](#)

[R24-5100](#) [R26-5100](#) [R28-5100](#) [R30-51000](#)