


High Density Specialty Filter

LFG120FHD

 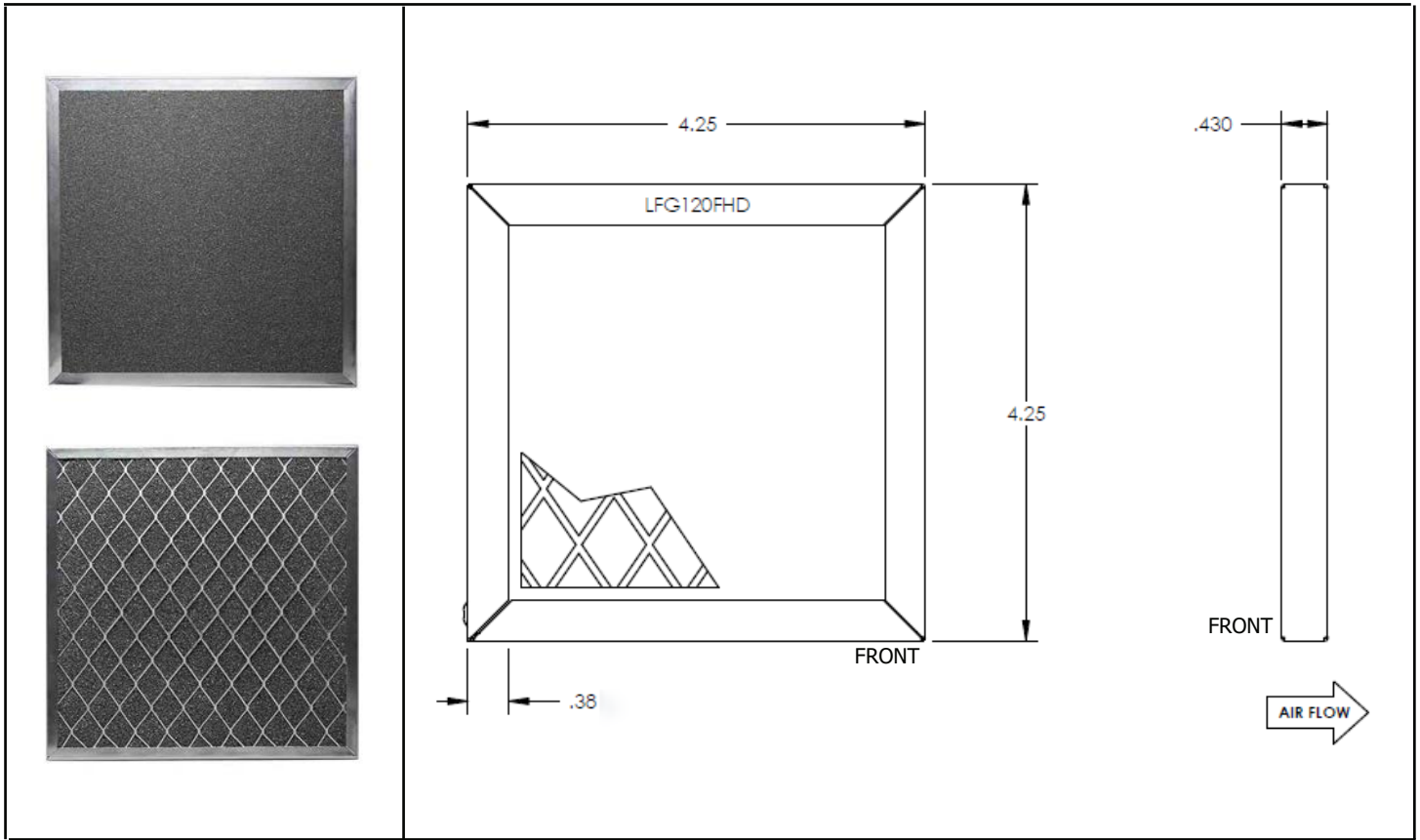


108 x 108 x 10.9mm (4.25" x 4.25" x 0.43")



Orion Fans high density air filters offer low pressure drop, fire resistance and the ability to capture large amounts of airborne dust in industrial enclosure applications. Designed for use in equipment where permanent, cleanable filters are most appropriate, these filters are ideal in networking, telecom and communications enclosures.

Part Number	LFG120FHD
Frame Description	Aluminum
Filter Material	45 PPI Gray High Density Foam, UL94 HF-1
Rivet Description	Aluminum
Grid Description	Aluminum Uni-grid support on downstream side
Matching Louvered Guards	LFGH120



Standards & Classifications

UL 900-2004, UL 94 HF-1
 NEBS GR-63-CORE
 NEBS GR-78-CORE
 NEMA
 IP
 MERV 5

MIL-STD
 ATCA
 MicroTCA
 CompactPCI
 FMVSS302

10557 Metric Drive
 Dallas, Texas 75243
 214-340-0265

RoHS Compliant

OrionFans.com
 Information and data is subject to
 change without prior notification.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[LFG120FHD](#)