


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2000 kcmil
Wire Type	Stranded Copper; Class B; Compressed or Concentric
Wire Strip Length	3-5/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	Brown
Panduit Die Index No. on Barrel	N/A
Alternate Industry Die Index No. () on Barrel	(34)

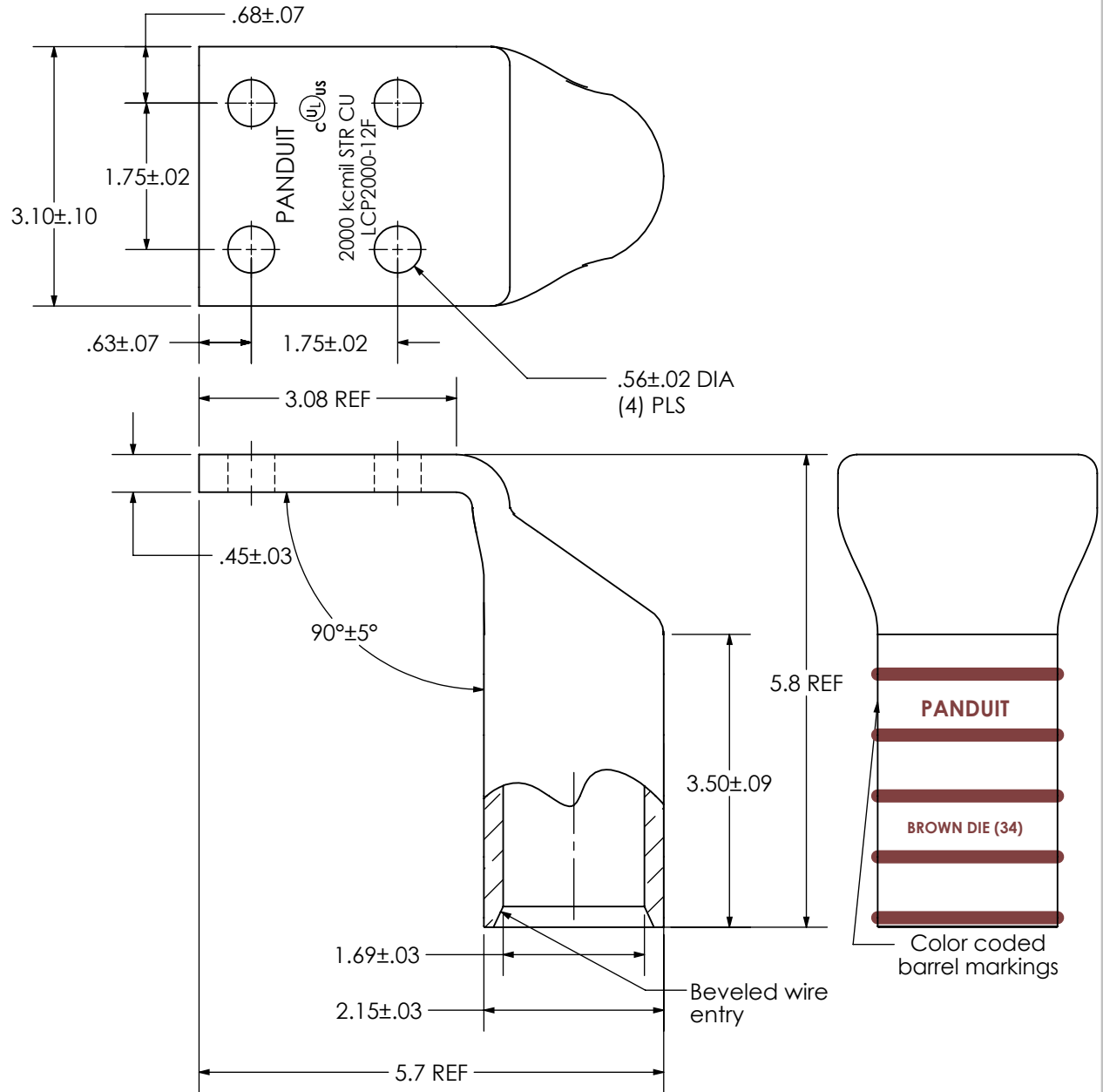

00	11/18	JHNU	JHNU
REV	DATE	BY	CHK

DRAWING RELEASED
DESCRIPTION

NPI-PWRGRD-042761
ECN

LCP2000-12F-1	
Copper Lug - Four-Hole, Long Barrel, 90° Bent Tongue	
SCALE	N/A
DRAWING NO / CAD FILE	LCP2000-12F-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[LCP2000-12F-1](#)