
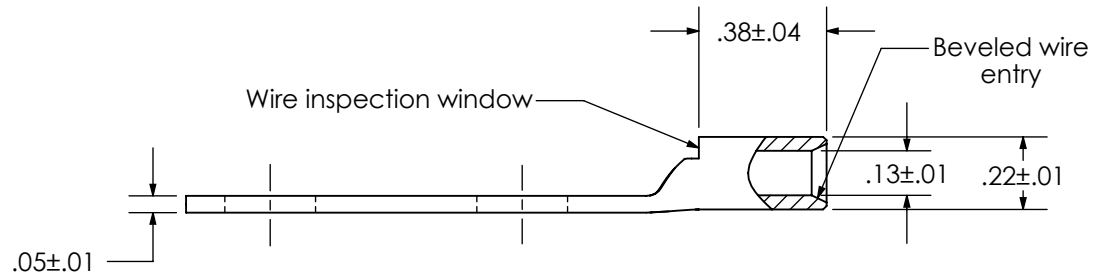


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

| | |
|--|--|
| Material | High Conductivity Seamless Copper Tube |
| Plating | Min .000050" Nickel underplate, Min .000200" Silver plating |
| Wire Size | 14 - 10 AWG STR, 12 - 10 AWG SOL |
| Wire Type | Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric |
| Wire Strip Length | 7/16 in. |
| Stud Size | 1/4 in. |
| UL Listed Wire Connector | Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. |
| UL Temperature Rating | 90° C |
| C.S.A Certified Wire Connector | N/A |
| Panduit Color Code on Barrel | N/A |
| Panduit Die Index No. on Barrel | N/A |
| Alternate Industry Die Index No. () on Barrel | N/A |

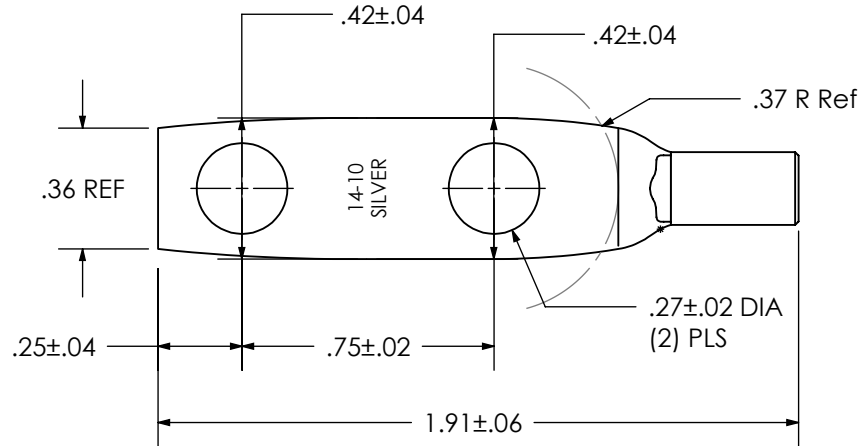

NOTE: DIMENSIONS AND TOLERANCES ARE IN INCHES

PANDUIT CORP. TINLEY PARK, ILLINOIS

LCD10-14BNS-L
Copper Lug - Two-Hole, Standard Barrel

| 06 | 6-23 | JHNU | DAEI | MRWA | B. REVISED TONGUE SHAPE A. ADDED TONGUE WIDTH DIMENSIONS | 129336 |
|-----|------|------|------|------|---|--------|
| REV | DATE | BY | CHK | APP | DESCRIPTION | ECN |

| | |
|--------------|---|
| SCALE N/A | DRAWING NO / CAD FILE LCD10-14BNS-CUST |
|--------------|---|

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[LCD10-14BNS-L](#)