

SPECIFICATIONS

NetKey faceplates shall be available in 1, 2, 3, 4, and 6-port single gang for vertical applications and 2-port and 4-port single gang for horizontal applications. Faceplates shall accept all NetKey modules for UTP, STP, fiber-optic, and audio/video applications. Faceplates shall be available in a flush or sloped design, and available with or without labels. Sloped design shall increase wall depth to improve the bend radius control.



TECHNICAL INFORMATION

Mounting options:	Screw holes with retention tabs, spaced for single gang openings; compatible with wall board adapter
Packaging:	Supplied with two 1 in. long, #6 – 32 slotted head screws; select styles include labels and label covers; faceplates without labels include matching mounting screws to match the faceplate; faceplates packaged one per bag, ten per box.

KEY FEATURES AND BENEFITS

Modular:	Accepts all NetKey modules which snap in and out for easy moves, adds, and changes
Identification:	Choice of adhesive labeling or dedicated label pocket for easy identification
Various port densities:	Provides design flexibility
Sloped design:	Allows proper bend radius control

APPLICATIONS

NetKey faceplates mount to any standard size single gang junction box and can also mount to a wall board adapter or raceway mounting brackets. When using NetKey faceplates with surface raceway, color matching is guaranteed. NetKey faceplates with label and label cover offer a quick and easy way to identify the ports. Mounting screw colors match the faceplate for a clean, consistent look. Dedicated sloped faceplates provide additional room for bend radius control to help comply with standards.

Vertical Sloped Faceplates with Labels

4-port: NK4VSFIW

Vertical Faceplates with Labels

1-port: NK1FIWY

2-port: NK2FIWY

4-port: NK4FIWY

6-port: NK6FIWY

Vertical Faceplates without Labels

1-port: NK1FNIW

2-port: NK2FNIW

3-port: NK3FNIW

4-port: NK4FNIW

Horizontal Faceplates Sloped with Labels

2-port: NK2HSFIWY

4-port: NK4HSFIWY

Double Gang Faceplate with Labels


10-port: NK8FIW

Wall Board Adapter

Single gang: MWBA1

Go to www.panduit.com for additional color options.

ENGINEERING DRAWINGS

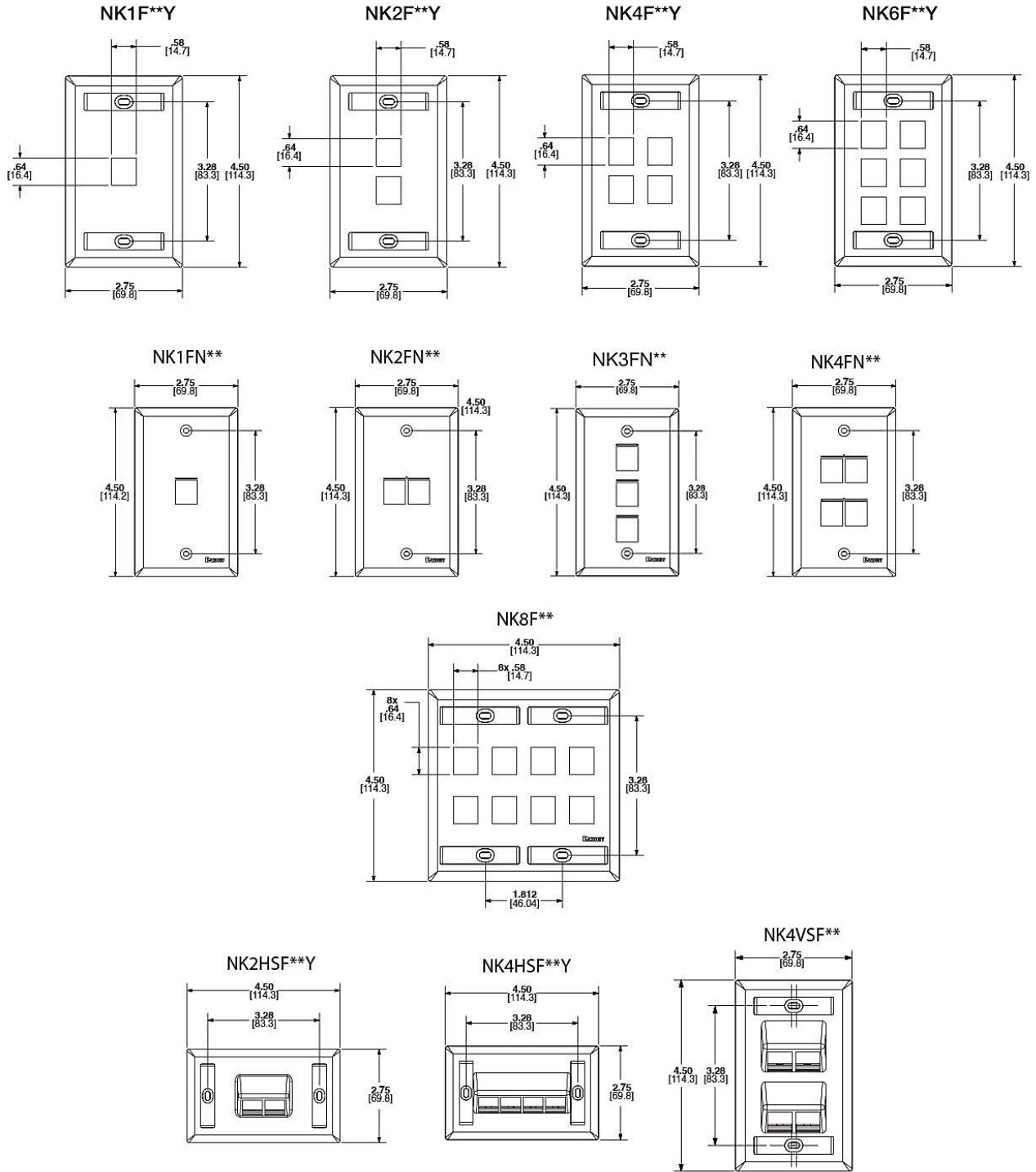

Dimensions are in inches. [Dimensions in brackets are metric].

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

PANDUIT®

For more information
Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

© 2024 Panduit Corp.
ALL RIGHTS RESERVED.
COSP649-WW-ENG
12/2024

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[NK4FNIW](#) [NK2FNIW](#) [NK1FNIW](#) [NK4FIWY](#) [NK1FIWY](#) [NK6FIWY](#) [NK2FIWY](#) [NK2FNEI](#) [NK1FWHY](#) [NK2FEIY](#)
[NK2FWHY](#) [NK3FNIW](#) [NK4FWHY](#) [NK6FWHY](#) [NK4FNEI](#) [NK8FIG](#) [NK4HSFIGY](#) [NK4VSFEI](#) [NK4FNIG](#)
[NK4HSFWHY](#) [NK4HSFIWY](#) [NK8FEI](#) [NK4FNBL](#) [NK4VSFIW](#) [NK8FIW](#) [NK4FNWH](#) [NK4HSFEIY](#) [NK8FWH](#)
[NK4VSFWH](#) [NK8FBL](#) [NK6FIGY](#) [NK4FBL](#) [NK6FBL](#) [NK3FNEI](#) [NK4FEIY](#) [NK6FEIY](#) [NK3FNWH](#) [NK4FIGY](#)
[NK1FNWH](#) [NK2FNWH](#) [NK1FEIY](#) [NK2FIGY](#) [NK2FBL](#) [NK2FNIG](#) [NK1FNEI](#) [NK1FIGY](#) [NK1FNBL](#) [NK1FBL](#)
[NK2HSFWHY](#) [NK2HSFIGY](#) [NK2HSFEIY](#) [NK2FNBL](#) [NK2HSFIWY](#) [NK1FNIG](#)