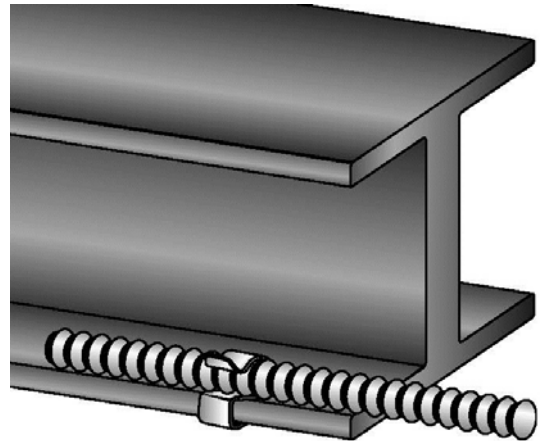
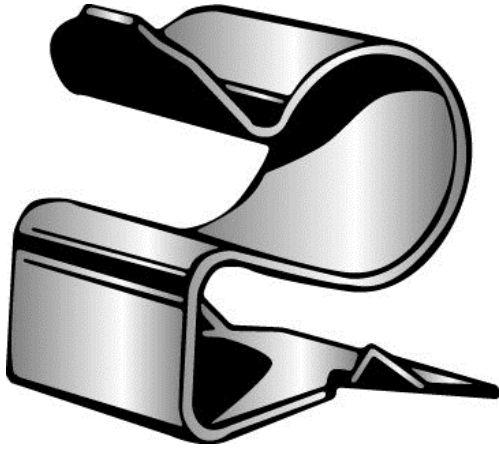


Part Number: PSC4A

Product Description: CABLE CLIP FOR .218" - .281" FLEXIBLE CABLE ON 3/16" - 9/32" FLANGE

**Material Specifications**

Type: High Carbon Steel, Spring Tempered, zinc co

Finish: Zinc Plated

Color: Silver

Function Specifications**Compatible Wires and Cables**

AC/MC CABLE (OD): .218 to .281

Drop Wire:

Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes:

Clearance Holes (in):

Threaded Rod Size (in):

Compatible Conduit

EMT Size (in):

Rigid/IMC (in):

Compatible Flanges and Studs

Flange Size (in): 3/16 to 9/32

Metal Stud Size (ins):

Static Load Rating

Vertical (lbs): Positioning Only

Horizontal (lbs): Positioning Only

Other**Codes and Regulatory**Regulatory
Certifications: -

Country of Origin: US

Packaging

General Packaging: Cardboard Box

Box Size: 7.5 X 4.25 X 3.313

Pieces per Package: 100

Other Box Features: Fold out handle

Document Information

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11203

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

PSC4A