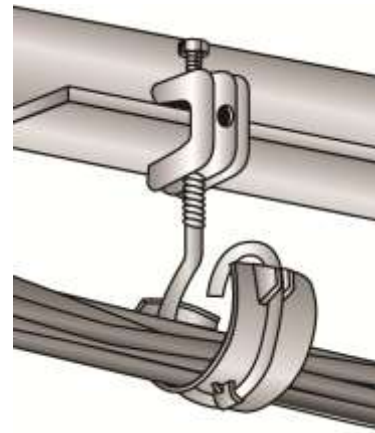


Part Number: BR-4.0-1/4-20S

Product Description: BRIDLE RING WITH SADDLE - 4" CAPACITY - MOUNTS WITH 1/4-20 THREADS

**Material Specifications**

Type: Assembly

Color: Various

Finish: Assembly

**Function Specifications****Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):


**Threaded Rods and Bolts**

Tapped Holes:

Clearance Holes (in):

Threaded Rod Size (in): 1/4"-20


**Compatible Conduit**

EMT Size (in):

Rigid/IMC (in):


**Compatible Flanges and Studs**

Flange Size (in):

Metal Stud Size (ins):


**Static Load Rating**

Vertical (lbs):

Horizontal (lbs):


**Other**

4" bridle ring with saddle

--

**Codes and Regulatory**Regulatory  
Certifications: UL/CUL

Country of Origin: US

--

--

**Packaging**

General Packaging: Cardboard Box

Box Size: 17 X 13.25 X 10

Pieces per Package: 50

Other Box Features:



**Document Information**

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11446

Revision Level: 0

ECN #: GAECN01813

Date: 3/19/2014



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[BR-4.0-1/4-20S](#)