




Search within category

GO

BUY NOW

DESIGN / INSTALL

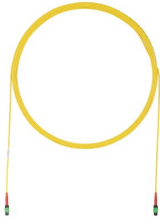

F9URLENENANM002

OS2 24-fiber, Interconnect, LSZH, 24F MPO Female to 24F MPO Female, Method A, Std IL, 2 m, Yellow.

Specs

Packaging Details

Documents

★ Add to Favorites

🛒 Add to BOM

Assembly Length Range	0-9 m (0-32 ft)
Cable Color	Yellow
Connector 1 Type	24F MPO
Connector 2 Type	24F MPO
Fiber Count	24
Fiber Type	OS2
Flammability Rating	Low Smoke Zero Halogen (LSZH)
Length (ft.)	6.56
Length (m)	2.0
Standards	TIA/EIA-598-C.3, Plenum Rated NFPA-262, LSZH-Rated, Meet IEC-60332, RoHS Compliant
RoHS Compliancy Status	Compliant
Min. Order Qty.	1.0000
Application	Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[F9URLENENANM002](#)