


Search within category **GO**

BUY NOW

DESIGN / INSTALL

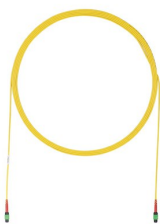

F9URPENENANF063

OS2 24-fiber, Interconnect, Plenum, 24F MPO Female to 24F MPO Female, Method A, Std IL, 63 ft, Yellow.

Specs **Packaging Details** **Documents**

★ [Add to Favorites](#) [Add to BOM](#)

Assembly Length Range	10-19 m (33-65 ft)
Cable Color	Yellow
Connector 1 Type	24F MPO
Connector 2 Type	24F MPO
Fiber Count	24
Fiber Type	OS2
Flammability Rating	Plenum (OFNP)
Length (ft.)	63.00
Length (m)	19.21
Standards	TIA/EIA-598-C.3, Plenum Rated NFPA-262, LSZH-Rated, Meet IEC-60332, RoHS Compliant
RoHS Compliancy Status	Compliant
Min. Order Qty.	1.0000
Application	Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[F9URPENENANF063](#)