


Search within category **GO**

BUY NOW

DESIGN / INSTALL

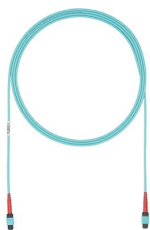

FXURPENENXNF037

OM3 24-fiber, Interconnect, Plenum, 24F MPO Female to 24F MPO Female, Method A, Optimized IL, 37 ft, Aqua.

Specs **Packaging Details** **Documents**

★ [Add to Favorites](#) [Add to BOM](#)

Application	Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure.
Assembly Length Range	10-19 m (33-65 ft)
Cable Color	Aqua
Connector 1 Type	24F MPO
Connector 2 Type	24F MPO
Fiber Count	24
Fiber Type	OM3
Flammability Rating	Plenum (OFNP)
Length (ft.)	37
Length (m)	11.28
Standards	TIA/EIA-598-C.3, NFPA-262, RoHS Compliant
RoHS Compliancy Status	Compliant
Min. Order Qty.	1.0000
No. of Fibers	24

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[FXURPENENXNF037](#)