

## USB female insert - VS-04-BUA-BUB-F/IP67 - 1653838


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



USB socket insert, 4-pos., socket USB type A on socket USB type B, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface, pluggable from both directions

RoHS

### Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 970161
GTIN	4017918970161

### Technical data

#### Ambient conditions

Ambient temperature (operation)	-15 °C ... 65 °C
---------------------------------	------------------

#### General data

Number of positions	4
Rated voltage (III/3)	30 V
Connection method	Socket, type B
Contact material	Copper alloy
Contact carrier material	Thermoplastic
Contact surface material	Gold over nickel
Housing material	PC

 
#### Standards and Regulations

Flammability rating according to UL 94	V0
--	----

### Drawings


## USB female insert - VS-04-BUA-BUB-F/IP67 - 1653838

Schematic diagram



Pin assignment socket USB, type A

Schematic diagram

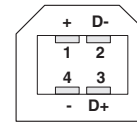

Pin assignment socket USB, type B

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1653838](#)