



Header - GMSTBA 2,5 HC/ 3-G-7,62 BG - 1701413

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

PCB headers, nominal current: 16 A, number of positions: 3, pitch: 7.62 mm, color: Pebble gray, contact surface: Tin, mounting: Wave soldering

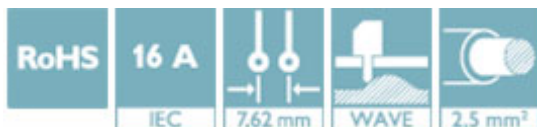

Key Commercial Data

Packing unit	50 pc
GTIN	 4 046356 530606
GTIN	4046356530606

Technical data

Dimensions

Length [l]	12 mm
Width	22.86 mm
Pitch	7.62 mm
Dimension a	15.24 mm
Width [w]	22.86 mm
Height [h]	12.1 mm
Height	8.6 mm
Length of the solder pin	3.5 mm
Length	12 mm

General

Range of articles	GMSTBA 2,5 HC/...G
Rated voltage (III/3)	500 V
Connection in acc. with standard	EN-VDE
Nominal current I _N	16 A
Color	Pebble gray
Number of positions	3

Standards and Regulations

Connection in acc. with standard	EN-VDE
	CUL

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
------------	---

Header - GMSTBA 2,5 HC/ 3-G-7,62 BG - 1701413

Technical data

Environmental Product Compliance

	No hazardous substances above threshold values
--	--

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1701413](#)