



GMSTBA 2,5 HC/ 3-G-7,62GY7035C - 1703944

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

PCB headers, nominal current: 16 A, number of positions: 3, pitch: 7.62 mm, color: light gray, contact surface: Tin, mounting: Wave soldering

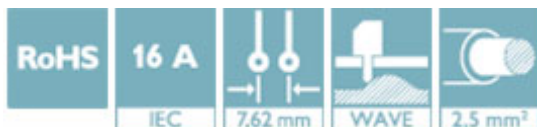

Key Commercial Data

Packing unit	50 pc
GTIN	 4 046356 670739
GTIN	4046356670739

Technical data

Dimensions

Pitch	7.62 mm
Dimension a	15.24 mm
Height	8.6 mm
Length of the solder pin	3.5 mm

General

Range of articles	GMSTBA 2,5 HC/...-G
Rated voltage (III/3)	500 V
Connection in acc. with standard	EN-VDE
Nominal current I _N	16 A
Color	light gray
Number of positions	3

Standards and Regulations

Connection in acc. with standard	EN-VDE
----------------------------------	--------

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Approvals

Approvals

GMSTBA 2,5 HC/ 3-G-7,62GY7035C - 1703944


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1703944](#)