



Printed-circuit board connector - PC 5/ 2-GU-7,62 GY7035 - 1713275

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

PCB headers, nominal current: 41 A, rated voltage (III/2): 630 V, number of positions: 2, pitch: 7.62 mm, color: light gray, contact surface: Tin, mounting: Wave soldering

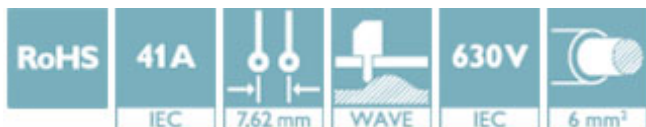

Key Commercial Data

Packing unit	50 pc
GTIN	 4 055626 355924
GTIN	4055626355924

Technical data

Dimensions

Length [l]	29.25 mm
Width	18.04 mm
Pitch	7.62 mm
Dimension a	7.62 mm
Width [w]	18.04 mm
Height [h]	17.74 mm
Height	13.54 mm
Length of the solder pin	4.2 mm
Pin spacing	7.62 mm
Length	29.25 mm

General

Range of articles	PC 5/..-GU
Insulating material group	I
Rated voltage (III/2)	630 V
Nominal current I _N	41 A
Insulating material	PA
Flammability rating according to UL 94	V0
Color	light gray
Number of positions	2

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Printed-circuit board connector - PC 5/ 2-GU-7,62 GY7035 - 1713275

Technical data

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Approvals


Approvals


Approvals

EAC / cULus Recognized

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------

cULus Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E60425-19920722
	D	B	C
Nominal voltage UN	600 V	300 V	150 V
Nominal current IN	5 A	41 A	41 A

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
 Flachsmarktstr. 8
 32825 Blomberg
 Germany
 Tel. +49 5235 300
 Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1713275](#)