

Screw insert - SF-BIT-SL 0,6X3,5-50 - 1212568

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Screw bit, bladed, E6.3-1/4" drive, size: 0.6 x 3.5 x 50 mm, hardened, suitable for holder according to DIN 3126-F6.3/ISO 1173

Your advantages

- ✓ Tools for SF-ASD 21 cordless screwdriver in various versions

Key Commercial Data

| | |
|--------------|---------------|
| Packing unit | 5 pc |
| GTIN | |
| GTIN | 4046356590037 |

Technical data

Dimensions

| | |
|-----------------|--------|
| Length (b) | 50 mm |
| Blade thickness | 0.6 mm |
| Blade width | 3.5 mm |
| Blade height | 20 mm |

General

| | |
|---------------|-------------------------------|
| Color | silver |
| Type | Bladed |
| Material | Steel |
| Test standard | DIN 3126 drive, output 3127-1 |

Standards and Regulations

| | |
|---------------|-------------------------------|
| Test standard | DIN 3126 drive, output 3127-1 |
|---------------|-------------------------------|


Environmental Product Compliance

| | |
|---------------------------|---|
| California Proposition 65 | Further information on California's prop. 65 is available under "Downloads" in the manufacturer's declaration |
|---------------------------|---|

Drawings

Screw insert - SF-BIT-SL 0,6X3,5-50 - 1212568

Pictogram

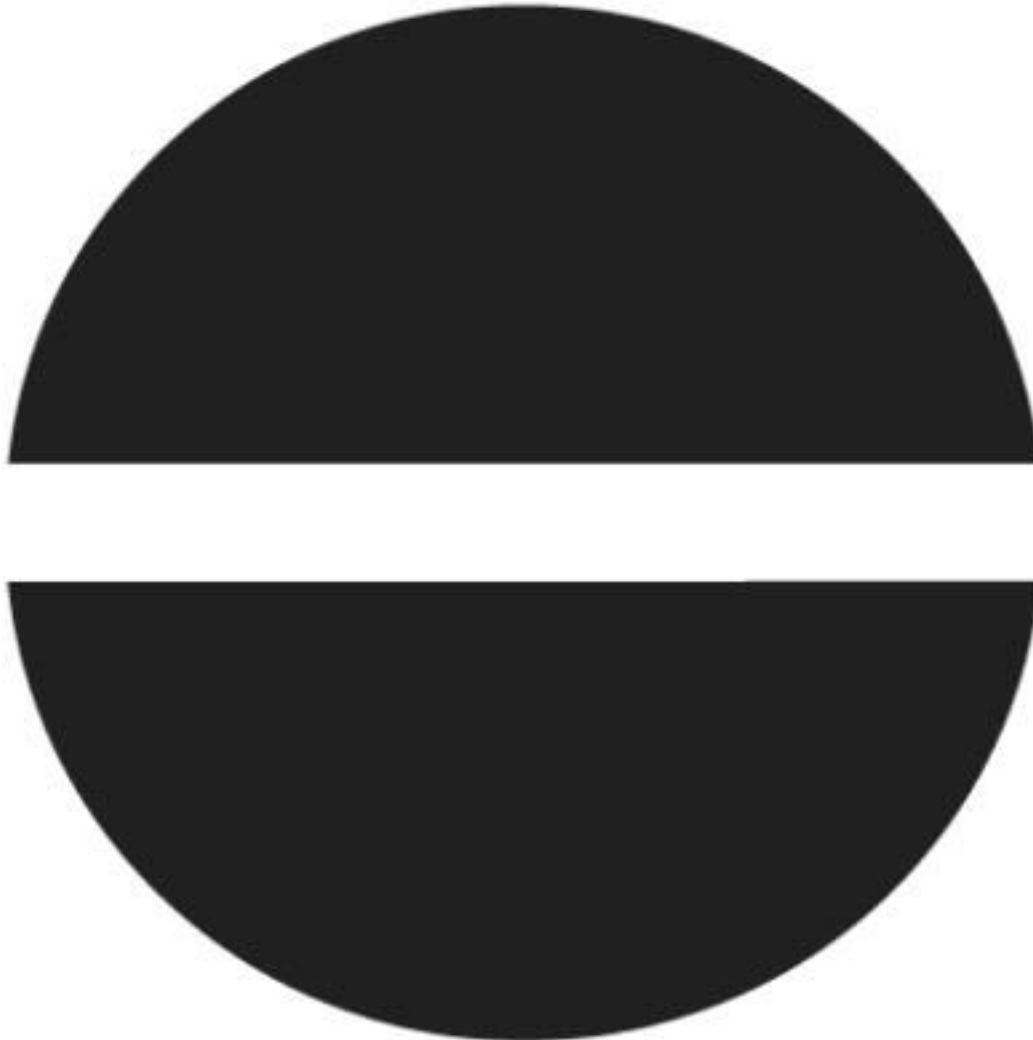

Classifications

eCl@ss

| | |
|---------------|----------|
| eCl@ss 10.0.1 | 21044204 |
| eCl@ss 4.0 | 21040400 |
| eCl@ss 4.1 | 21040400 |
| eCl@ss 5.0 | 21040400 |
| eCl@ss 5.1 | 21040400 |
| eCl@ss 6.0 | 21049200 |
| eCl@ss 7.0 | 21044204 |
| eCl@ss 8.0 | 21044204 |
| eCl@ss 9.0 | 21044204 |

Screw insert - SF-BIT-SL 0,6X3,5-50 - 1212568

Classifications

ETIM

| | |
|----------|----------|
| ETIM 4.0 | EC002115 |
| ETIM 5.0 | EC002116 |
| ETIM 6.0 | EC002116 |
| ETIM 7.0 | EC002116 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 27111701 |
| UNSPSC 7.0901 | 27111701 |
| UNSPSC 11 | 27111701 |
| UNSPSC 12.01 | 27111701 |
| UNSPSC 13.2 | 27111701 |
| UNSPSC 18.0 | 27112814 |
| UNSPSC 19.0 | 27112814 |
| UNSPSC 20.0 | 27112814 |
| UNSPSC 21.0 | 27112814 |

Approvals


Approvals

Approvals

EAC

Ex Approvals

Approval details

| | | |
|-----|---|--------------------------|
| EAC |  | RU C- DE.AI30.B.01750 |
|-----|---|--------------------------|

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1212568](#)