

Screwdriver - SZS 0,6X3,5 VDE - 1212602

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Screwdriver, slot-headed, VDE insulated, size: 0.6 x 3.5 x 100 mm, 2-component grip, with non-slip grip

Your advantages

- ✓ The tools feature ergonomic two-component safety handles
- ✓ Large contact surface of blades inside screw head
- ✓ Individually tested safety screwdrivers according to DIN EN 60900 (VDE 0682-201)
- ✓ For working on or in the vicinity of live parts up to 1000 V AC or 1500 V DC

Key Commercial Data

Packing unit	10 pc
GTIN	 4 046356 590761
GTIN	4046356590761

Technical data

Dimensions

Length (b)	181 mm
Width (a)	26 mm
Blade thickness	0.6 mm
Blade width	3.5 mm
Blade height	100 mm
Wrench size	0 mm

General

Type	Bladed
	straight
Material	alloyed tool steel
Test standard	DIN/ISO 2380-1 IEC 60900:2004
Weight	35 g

Standards and Regulations

Test standard	DIN/ISO 2380-1 IEC 60900:2004
---------------	-------------------------------

Environmental Product Compliance

Screwdriver - SZS 0,6X3,5 VDE - 1212602


Technical data

Environmental Product Compliance

California Proposition 65	Further information on California's prop. 65 is available under "Downloads" in the manufacturer's declaration
---------------------------	---------------------------------------------------------------------------------------------------------------


Drawings

Pictogram

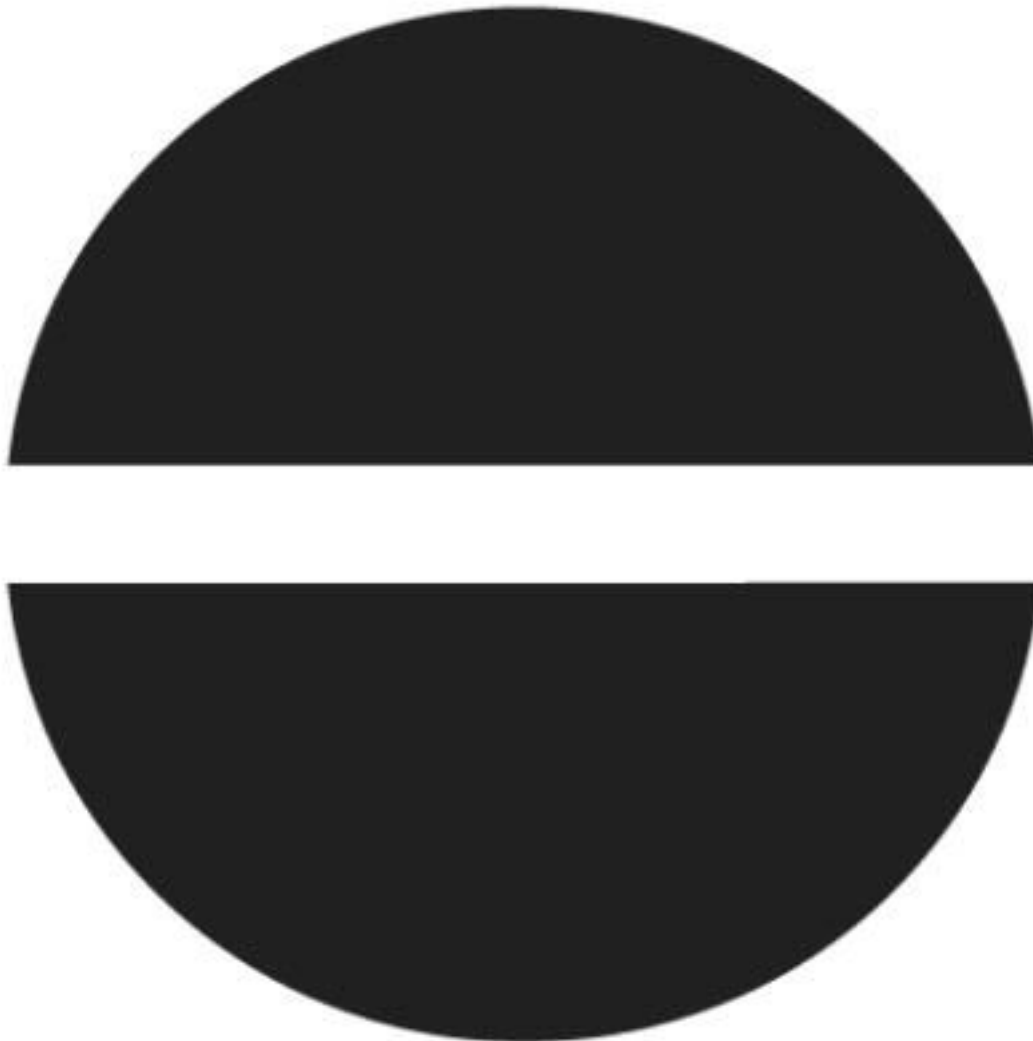

Screwdriver - SZS 0,6X3,5 VDE - 1212602

Dimensional drawing

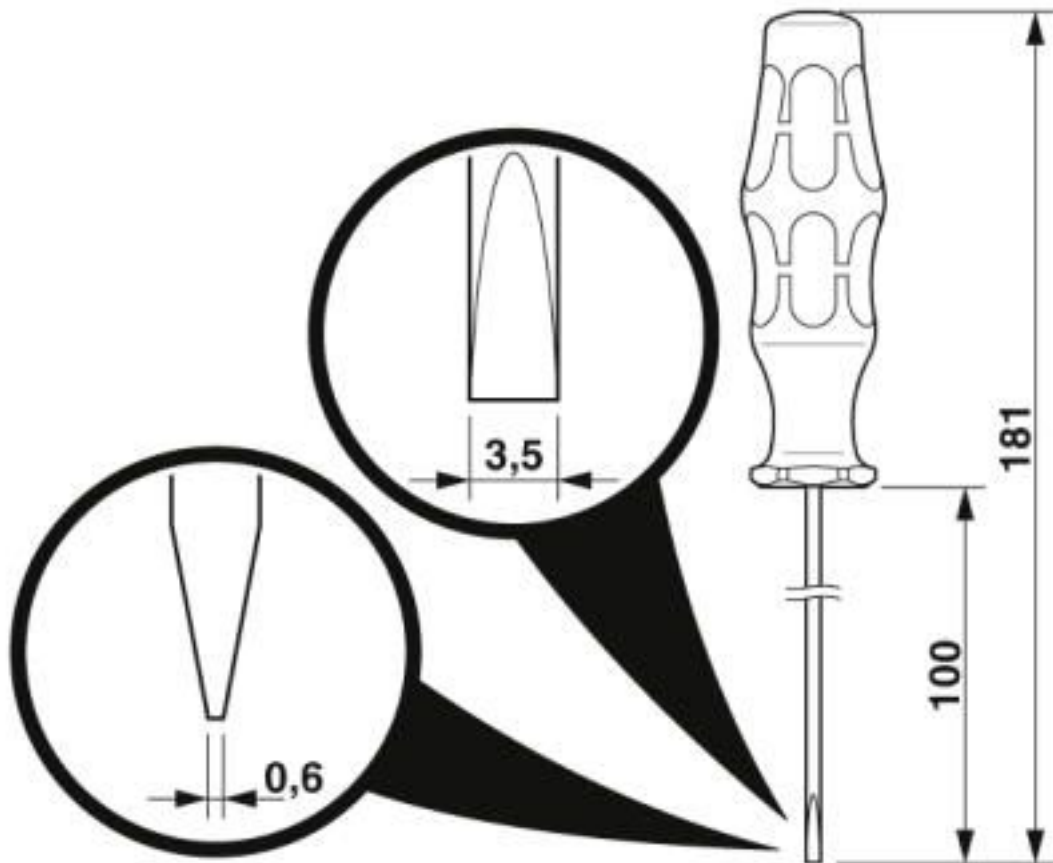

Classifications

eCl@ss

eCl@ss 10.0.1	21040407
eCl@ss 4.0	21040200
eCl@ss 4.1	21040200
eCl@ss 5.0	21040200
eCl@ss 5.1	21040200
eCl@ss 6.0	21040400
eCl@ss 7.0	21040407
eCl@ss 8.0	21040407
eCl@ss 9.0	21040407

ETIM

ETIM 2.0	EC000158
ETIM 3.0	EC000158
ETIM 4.0	EC000158
ETIM 5.0	EC000158
ETIM 6.0	EC000158

Screwdriver - SZS 0,6X3,5 VDE - 1212602

Classifications

ETIM

ETIM 7.0	EC000158
----------	----------

UNSPSC

UNSPSC 6.01	27111701
UNSPSC 7.0901	27111701
UNSPSC 11	27111701
UNSPSC 12.01	27111701
UNSPSC 13.2	27111701
UNSPSC 18.0	27111701
UNSPSC 19.0	27111701
UNSPSC 20.0	27111701
UNSPSC 21.0	27111701

Approvals


Approvals

Approvals

VDE Zeichengenehmigung / EAC

Ex Approvals

Approval details

VDE Zeichengenehmigung		http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx	086858
------------------------	-------------------------------------------------------------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	--------

EAC		RU x- DE.xx08.B.02974
-----	-------------------------------------------------------------------------------------	--------------------------

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1212602](#)