

Protective covers - HC-STA-D07-BCSFS-PL-BK - 1419273

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Protective cover D7, for single locking latch, material: PA, protective cover material: PA, height: 30 mm, seal: no, Standard, with lanyard, diameter of retaining cord eyelet: 4 mm, for pin inserts



COMPLETE RoHS

Key Commercial Data

| | |
|--------------|---|
| Packing unit | 1 pc |
| GTIN |  4 055626 160245 |
| GTIN | 4055626160245 |

Technical data

Dimensions

| | |
|--------|---------|
| Height | 30 mm |
| Width | 26.5 mm |
| Length | 26.5 mm |

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection (IP) | IP54 |
| | IP65 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

General

| | |
|----------------------------|---|
| Note | For use on the panel mounting base |
| Size | D7 |
| Type | for supporting base element with single locking latch |
| Housing type | Protective cover |
| Color | black |
| Locking type | for single locking latch |
| Material | PA |
| Housing material | PA |
| Material, protective cover | PA |

Protective covers - HC-STA-D07-BCSFS-PL-BK - 1419273

Technical data

General


| | |
|--|--|
| Flammability rating according to UL 94 | V0 (Polyamide housing) |
| Connection | Plastic protective cover for short-term protection |

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally Friendly Use Period = 50 years |
| | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

Drawings

Dimensional drawing

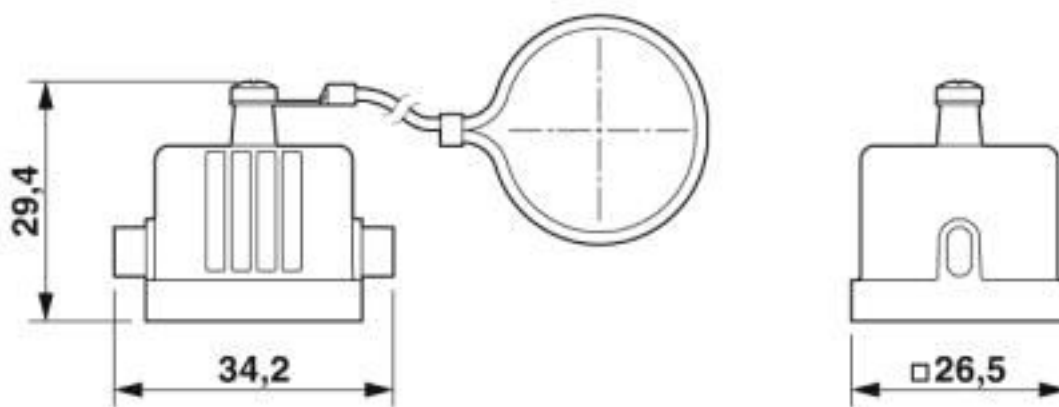

Dimensional drawing

Classifications

eCl@ss

| | |
|---------------|----------|
| eCl@ss 10.0.1 | 27440208 |
| eCl@ss 4.0 | 27141200 |
| eCl@ss 4.1 | 27141200 |
| eCl@ss 5.0 | 27149100 |
| eCl@ss 5.1 | 27149100 |
| eCl@ss 6.0 | 27261200 |
| eCl@ss 7.0 | 27440208 |
| eCl@ss 8.0 | 27440208 |
| eCl@ss 9.0 | 27440208 |

ETIM

| | |
|----------|----------|
| ETIM 5.0 | EC002314 |
| ETIM 6.0 | EC002314 |
| ETIM 7.0 | EC002314 |

Protective covers - HC-STA-D07-BCSFS-PL-BK - 1419273

Classifications

UNSPSC

| | |
|-------------|----------|
| UNSPSC 13.2 | 39121421 |
| UNSPSC 18.0 | 39121421 |
| UNSPSC 19.0 | 39121421 |
| UNSPSC 20.0 | 39121421 |
| UNSPSC 21.0 | 39121421 |

Approvals

Approvals

Approvals

EAC / DNV GL

Ex Approvals

Approval details

| | | |
|-----|--|--------------------------|
| EAC | | RU C- DE.AI30.B.01102 |
|-----|--|--------------------------|

| | | | |
|--------|--|---|------------|
| DNV GL | | https://approvalfinder.dnvgl.com/ | TAE000037S |
|--------|--|---|------------|

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1419273](#)