

## Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Power cable, 4-position, PVC, black-gray RAL 7021, Plug straight M12, coding: T, on Socket straight M12, coding: T, cable length: 2 m, For direct current up to 12 A/63 V

### Your advantages

- ✓ Easy and safe: 100% electrically tested plug-in components
- ✓ High-performance: DC connectors for up to 12 A and 63 V DC
- ✓ Protection against incorrect connection using special T-coding

### Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 898650
GTIN	4055626898650

### Technical data


#### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

### Drawings


# Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997

Dimensional drawing

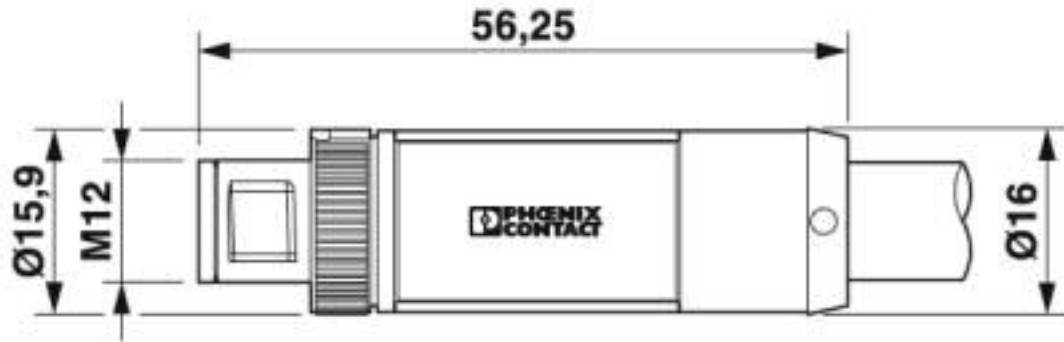


Plug, M12 x 1, straight

Dimensional drawing

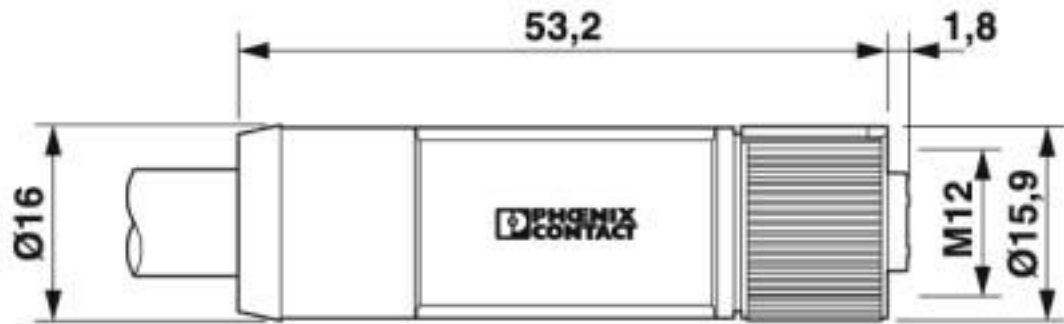

M12 x 1 socket, straight


Circuit diagram

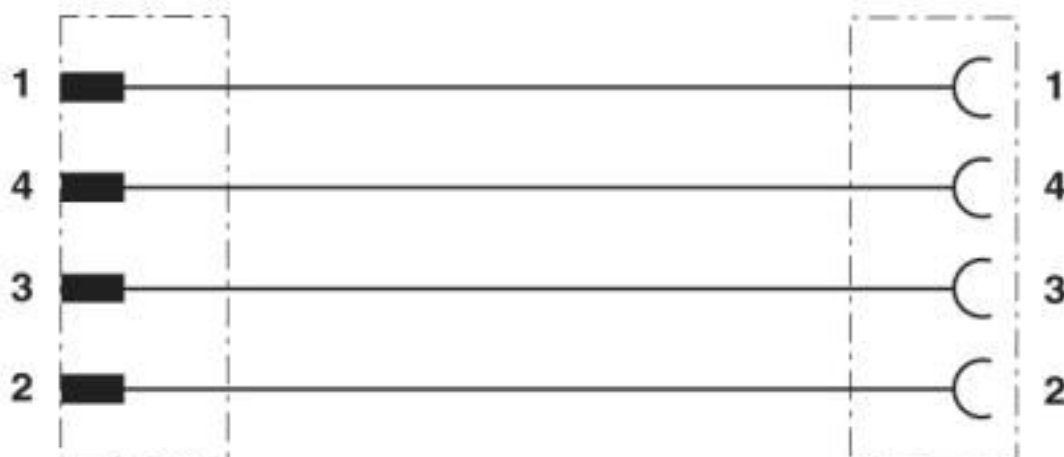

Contact assignment of the M12 connector and the M12 socket

## Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997


Schematic diagram

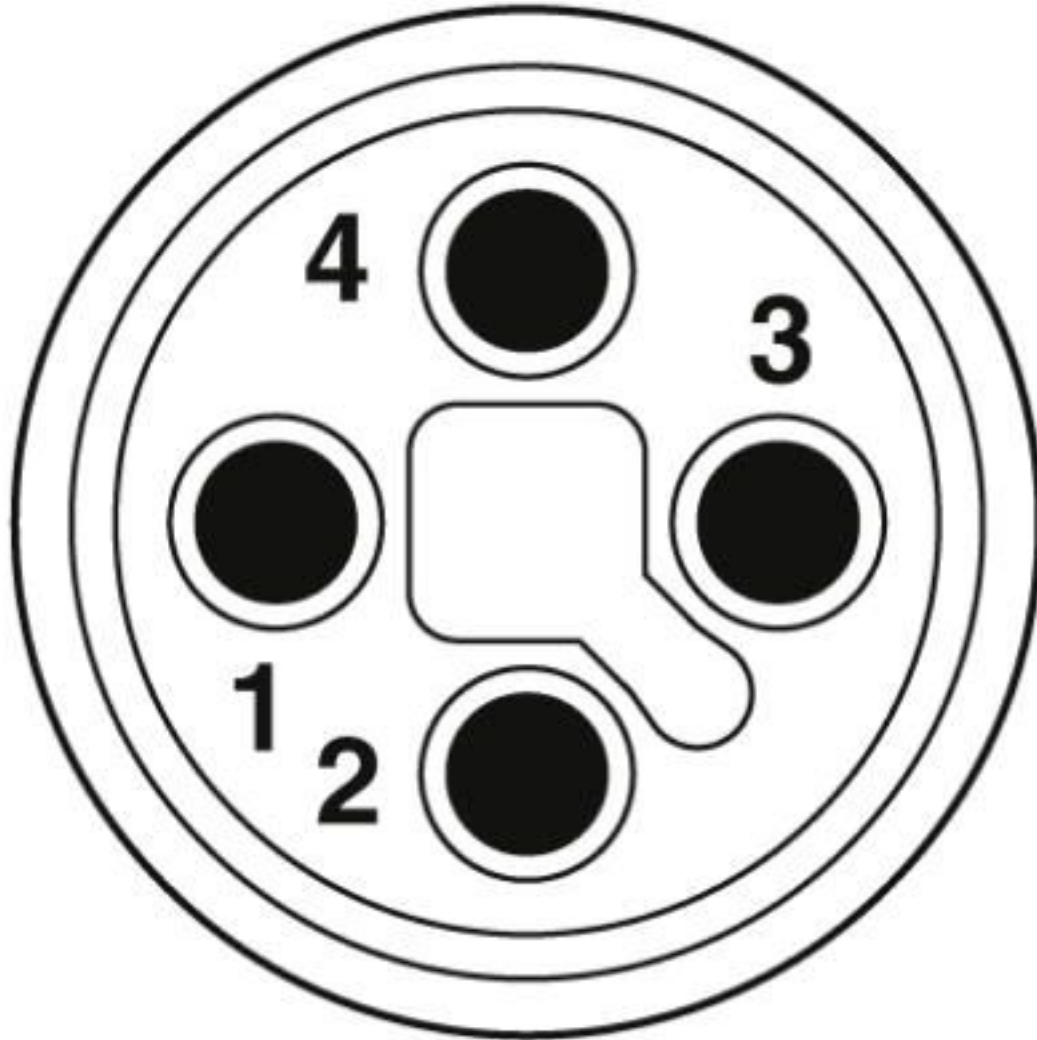

Pin assignment for M12 plug, 4-pos., T-coded, view of plug side

# Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997


Schematic diagram

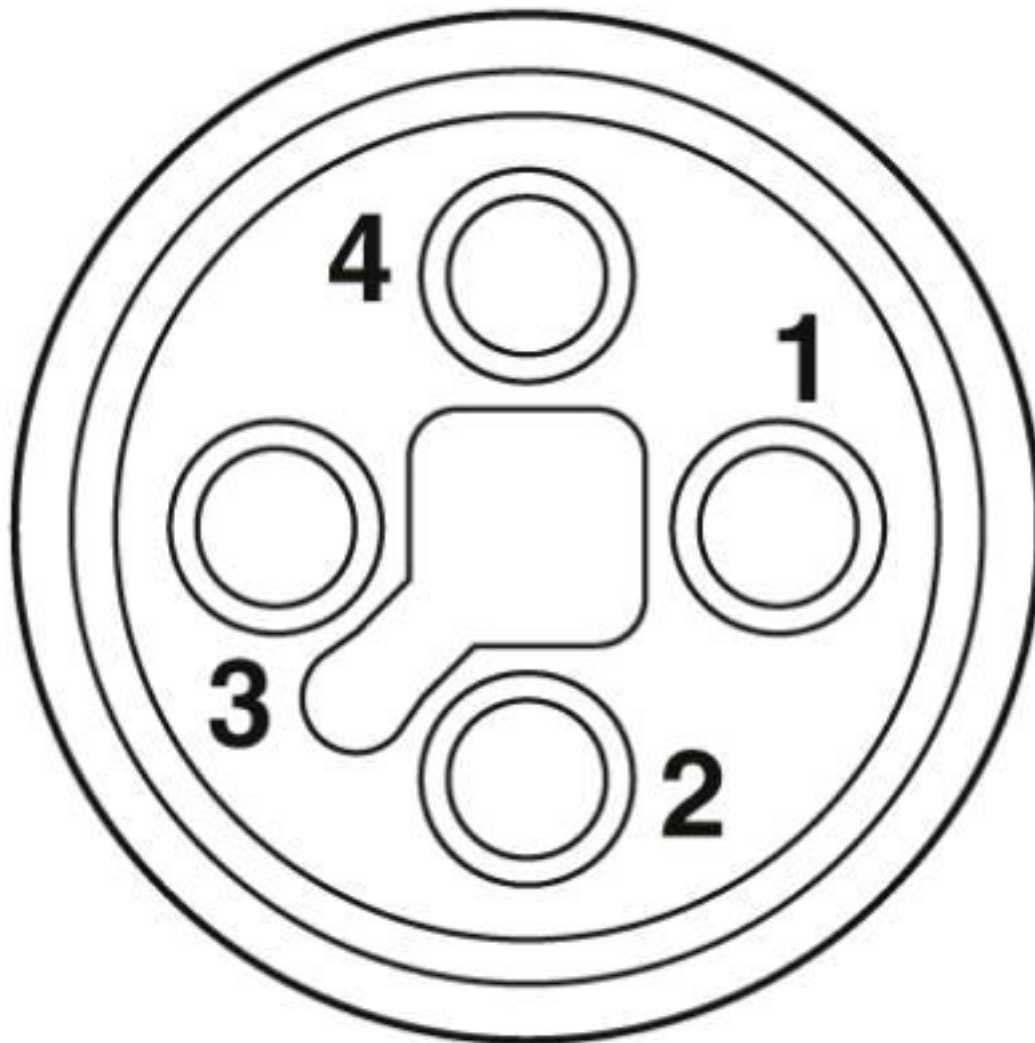

Pin assignment of M12 socket, 4-pos., T-coded, socket side view

# Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997

Cable cross section

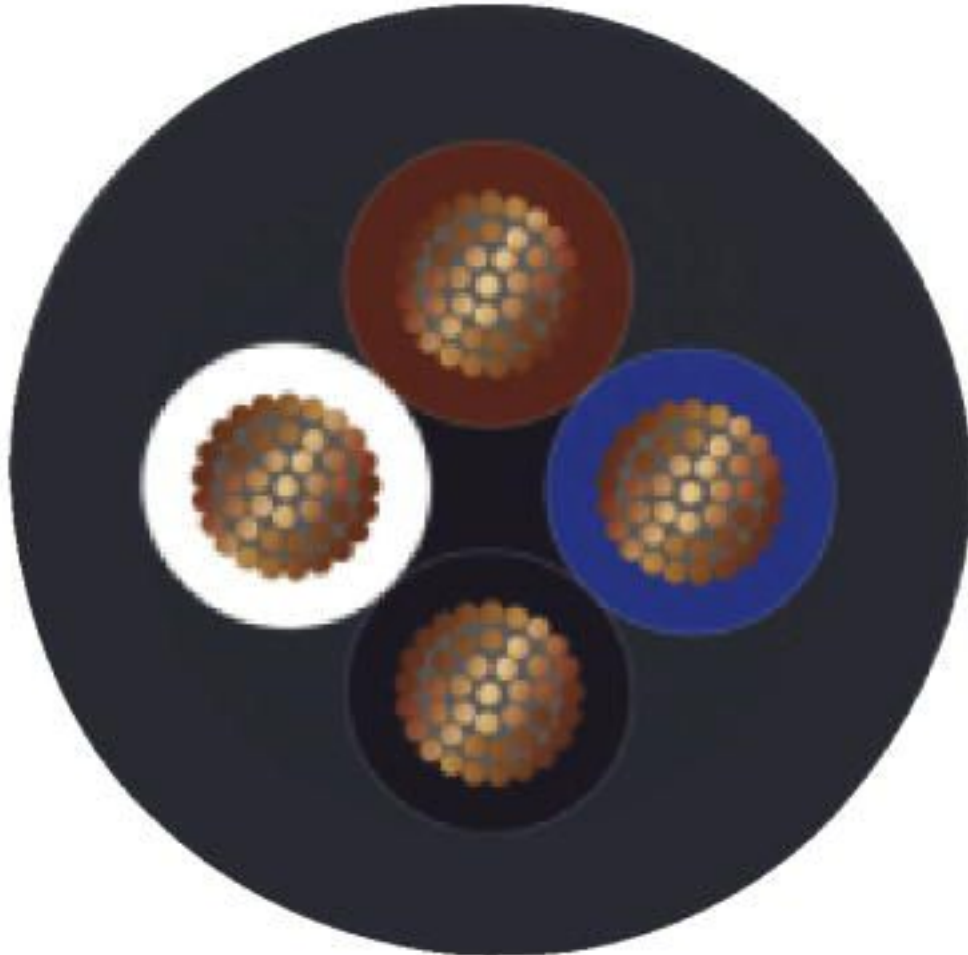

PVC black [110]

## Classifications

eCl@ss

eCl@ss 10.0.1	27060311
eCl@ss 6.0	27279200
eCl@ss 7.0	27279218
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311

ETIM

ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

# Power cable - SAC-4P-M12MST/ 2,0-110/M12FST - 1089997

## Approvals

Approvals

---

Approvals

EAC-RoHS / EAC

---

Ex Approvals

---

## Approval details

EAC-RoHS		RU D- DE.HB35.B.00385
----------	--	--------------------------

EAC		RU C- DE.BL08.B.00286
-----	--	--------------------------

## Accessories

Accessories

Screwdriver tools

Tool - SAC BIT M12-D16 - 1200305



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, knurl diameter: 16 mm, for 4 mm hexagonal drive

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1089997](#)