

Pressure screw - HC-DS-PG36-Z - 1772667

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Pressure screws, with strain relief clamps, nickel-plated brass, clamping area 25.5 mm ... 34 mm, type Pg36



Key Commercial Data

Packing unit	10 pc
GTIN	
GTIN	4017918037321

Technical data

Dimensions

Wrench size, union nut	52 mm
Clamping range of the strain relief clip	26.00 mm ... 34.00 mm

General

Material, pressure screw	Nickel-plated brass
--------------------------	---------------------


Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Pressure screw - HC-DS-PG36-Z - 1772667

Dimensional drawing

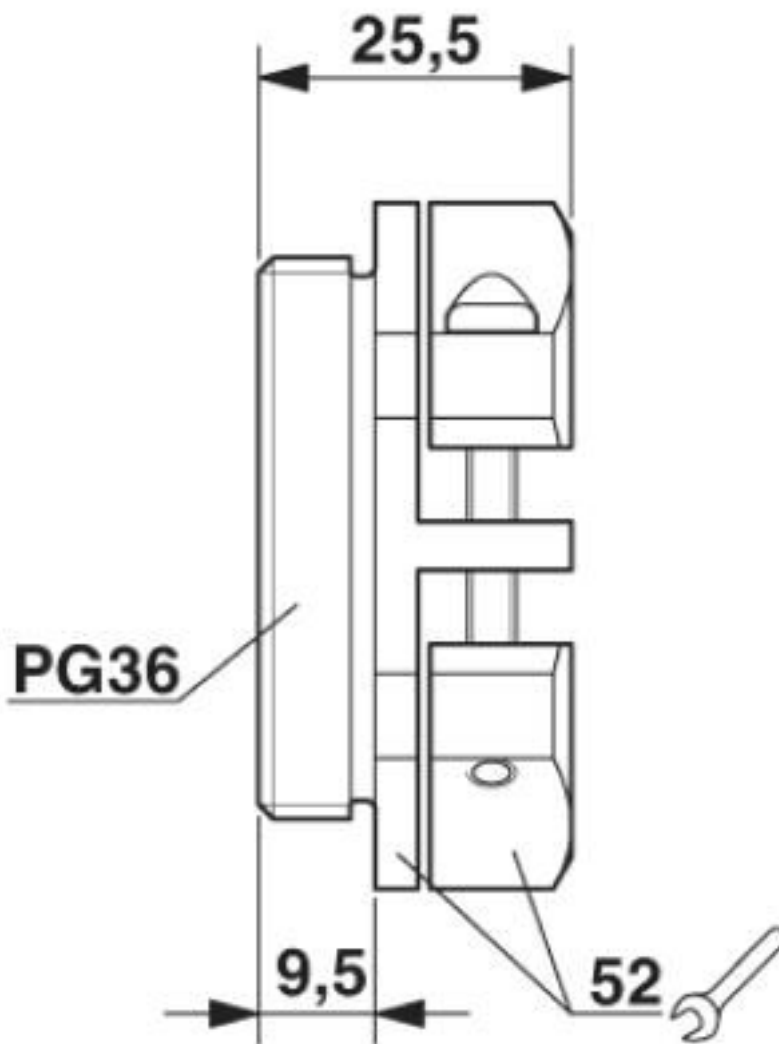

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27144420
eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27149100
eCl@ss 5.1	27149100
eCl@ss 6.0	27149100
eCl@ss 7.0	27069215
eCl@ss 8.0	27069215

Pressure screw - HC-DS-PG36-Z - 1772667

Classifications

eCl@ss

eCl@ss 9.0	27144420
------------	----------

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 5.0	EC000814
ETIM 6.0	EC000814
ETIM 7.0	EC000814

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	31161514
UNSPSC 18.0	31161514
UNSPSC 19.0	31161514
UNSPSC 20.0	31161514
UNSPSC 21.0	31161514

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1772667](#)