

## Side element - UM-ALU 4-72 COVER AL - 2200933

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Press-drawn section housings, Side elements (left and right) incl. snap-on foot and screws for basic profile, width: 75.4 mm, height: 2 mm, color: aluminum color



### Your advantages

- Item is from the UM-ALU product range
- Aluminum press-drawn section
- Available in lengths from 42.5 mm ... 990 mm, can be cut to any length
- Available in overall widths of 75 mm and 105 mm
- Variety of connection technologies
- Can be mounted on the DIN rail
- EMC protection



### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356716512

### Technical data

#### Product properties

Brief article description	Side element
Type	UM-ALU 4-72 COVER AL
Order No.	2200933
Housing type	Press-drawn section housings
Type	Side elements (left and right) incl. snap-on foot and screws for basic profile
Max. IP code to attain	IP40
Mounting type	Screw mounting

#### Dimensions

## Side element - UM-ALU 4-72 COVER AL - 2200933

### Technical data

#### Dimensions

Width [ w ]	75.4 mm
Height [ h ]	2 mm
Depth [ d ]	31 mm

#### Material specifications

Material	Aluminum
Color	aluminum color
Surface characteristics	anodized

#### Ambient conditions

Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)

#### Note on mounting

Tightening torque / rotational speed	Screw connection with the basic profile: 0.8 Nm-1 Nm / rpm- rpm
--------------------------------------	---

#### Packaging specifications

Type of packaging	packed in cardboard
Pieces per package	1
Denomination packing units	Pcs.
Outer packaging type	Carton

#### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

### Classifications

#### eCl@ss

eCl@ss 10.0.1	27182701
eCl@ss 4.0	27180400
eCl@ss 4.1	27180400
eCl@ss 5.0	27180500
eCl@ss 5.1	27180500
eCl@ss 6.0	27182000
eCl@ss 7.0	27182701
eCl@ss 8.0	27182701
eCl@ss 9.0	27182701

#### ETIM

ETIM 3.0	EC001031
ETIM 4.0	EC000721
ETIM 5.0	EC002779

# Side element - UM-ALU 4-72 COVER AL - 2200933

## Classifications

### ETIM

ETIM 6.0	EC002779
ETIM 7.0	EC002779

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

## Approvals

### Approvals

---

### Approvals

### EAC

---

### Ex Approvals

---

### Approval details

EAC		B.01742
-----	--	---------

## Accessories

### Accessories

### Component housing lower part

### Profile - UM-ALU 4-72 PROFILE 42,5 - 2200917



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 42.5 mm, color: aluminum color

## Side element - UM-ALU 4-72 COVER AL - 2200933

### Accessories


Profile - UM-ALU 4-72 PROFILE 60 - 2200918



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 60 mm, color: aluminum color

---

Profile - UM-ALU 4-72 PROFILE 95 - 2200919

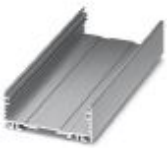

Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 95 mm, color: aluminum color

---

Profile - UM-ALU 4-72 PROFILE 130 - 2200920



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 130 mm, color: aluminum color

---

Profile - UM-ALU 4-72 PROFILE 165 - 2200921



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 165 mm, color: aluminum color

---

Profile - UM-ALU 4-72 PROFILE 200 - 2200922



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 200 mm, color: aluminum color

---

## Side element - UM-ALU 4-72 COVER AL - 2200933

### Accessories

Profile - UM-ALU 4-72 PROFILE 235 - 2200923



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 235 mm, color: aluminum color

---


Profile - UM-ALU 4-72 PROFILE 990 - 2200924



Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 990 mm, color: aluminum color

---

Profile - UM-ALU 4-72 PROFILE 111 - 2201930

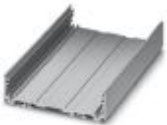

Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 111 mm, color: aluminum color

---

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[2200933](#)