

## Fork-type cable lug - C-FCI 2,5/M4 - 3240039

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Fork-type cable lug, blue, 1.5 - 2.5 mm<sup>2</sup>, M4

### Your advantages

- ✓ The fork-type cable lugs without plastic sleeve feature a hard-soldered neck. In conjunction with the CRIMPFOX-RC ... and CRIMPFOX-RCI ... pliers they can be used to achieve maximum conductor pull-out forces
- ✓ The insulated versions are halogen-free and feature "EASY ENTRY" technology

### Key Commercial Data

|              |   |
|--------------|---|
| Packing unit | 100 pc  |
| GTIN         | <br>4 046356 451161 |
| GTIN         | 4046356451161   |

### Technical data

#### Dimensions

|   |         |
|---|---------|
| Length (b)  | 22.5 mm |
| Width (a)   | 7.2 mm  |
| Maximum stripping length                                  | 8 mm    |
| Length of insulation sleeve (c)                           | 11 mm   |
| Inner dimension of the insulating collar (d)              | 4.5 mm  |
| Distance between the center and the insulation sleeve (e) | 6.5 mm  |
| Inner diameter (f)  | 4.3 mm  |
| Material thickness (g)                                    | 0.8 mm  |

#### General

|  |              |
|--|--------------|
| Color                                  | blue         |
| Stripping length                       | 8 mm         |
| Components                             | halogen-free |
| Flammability rating according to UL 94 | V2           |

# Fork-type cable lug - C-FCI 2,5/M4 - 3240039

## Technical data

### General

|                     |            |
|---------------------|------------|
| Material            | Copper     |
| Insulating material | PA         |
| Coating             | tin-plated |

### Standards and Regulations


|  |    |
|--|----|
| Flammability rating according to UL 94 | V2 |
|--|----|

### Environmental Product Compliance

|            |   |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Drawings

Dimensional drawing

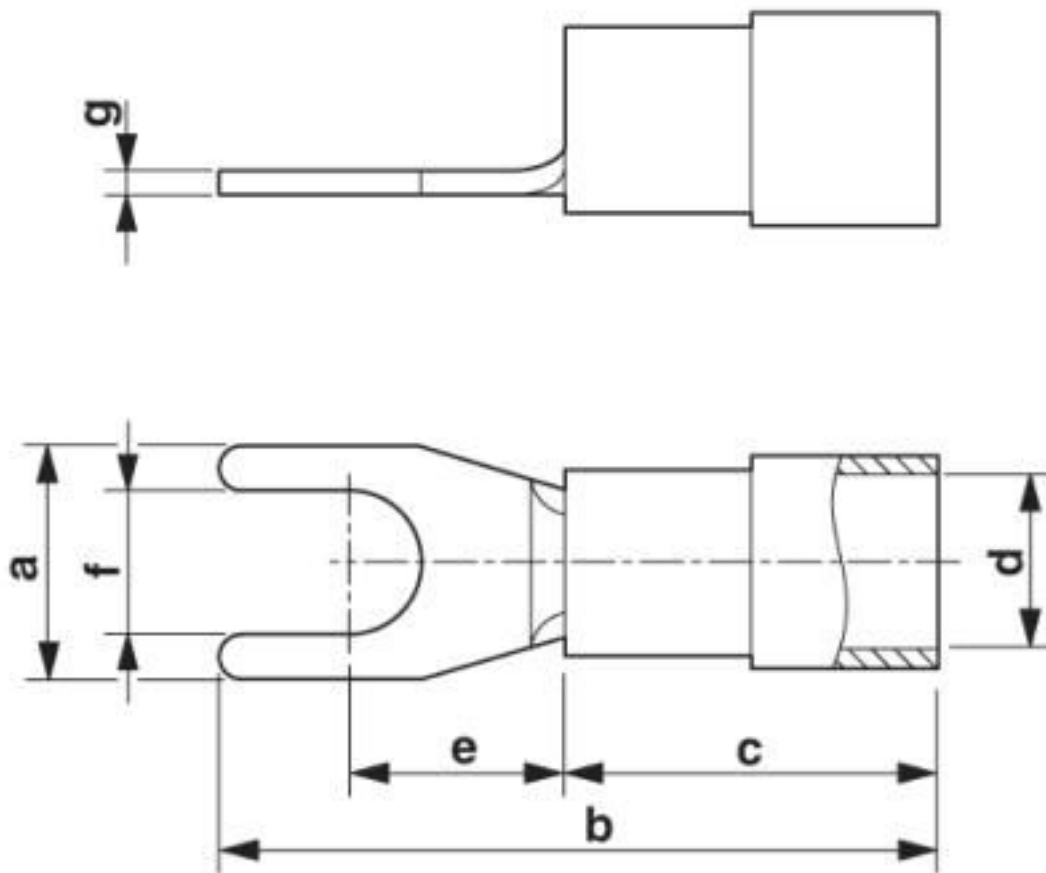

## Classifications

eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27400204 |
|---------------|----------|

## Fork-type cable lug - C-FCI 2,5/M4 - 3240039

### Classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27060700 |
| eCl@ss 4.1 | 27060700 |
| eCl@ss 5.0 | 27400200 |
| eCl@ss 5.1 | 27400200 |
| eCl@ss 6.0 | 27400200 |
| eCl@ss 7.0 | 27400204 |
| eCl@ss 8.0 | 27400204 |
| eCl@ss 9.0 | 27400204 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000005 |
| ETIM 3.0 | EC000005 |
| ETIM 4.0 | EC001052 |
| ETIM 5.0 | EC001052 |
| ETIM 6.0 | EC001052 |
| ETIM 7.0 | EC001052 |

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 27113201 |
| UNSPSC 7.0901 | 27121703 |
| UNSPSC 11     | 27121703 |
| UNSPSC 12.01  | 27121703 |
| UNSPSC 13.2   | 27121707 |
| UNSPSC 18.0   | 27121707 |
| UNSPSC 19.0   | 27121707 |
| UNSPSC 20.0   | 27121707 |
| UNSPSC 21.0   | 27121707 |

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[3240039](#)