

## Cable duct - CD 120X80 - 3240202

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable duct for installation and mounting in control cabinets, gray, comprising upper part and mounting base, width: 120 mm, height: 80 mm, length: 2000 mm

### Your advantages

- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Predetermined breaking point enables tool-free, burr-free removal of bars
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool



### Key Commercial Data

Packing unit	4 pc
Minimum order quantity	8 pc
GTIN	
GTIN	4046356459266

### Technical data

#### Dimensions

Length (b)	2000 mm
Width (a)	120 mm
Height (c)	80 mm

#### Ambient conditions

Ambient temperature (operation)	-5 °C ... 60 °C
---------------------------------	-----------------

#### General

Color	gray
Components	Lead-free
Flammability rating according to UL 94	V0

# Cable duct - CD 120X80 - 3240202

## Technical data

### General

Material	PVC
Nominal cross section	6737 mm <sup>2</sup>

### Standards and Regulations


Halogen-free	no
Connection in acc. with standard	CSA
Flammability rating according to UL 94	V0

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

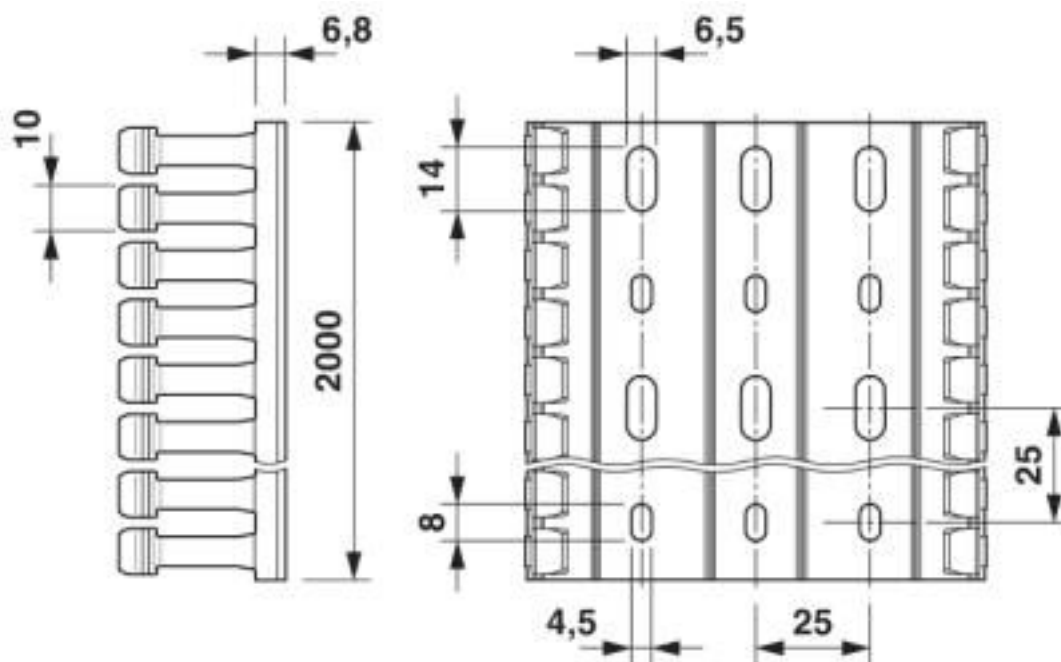

Base perforation according to DIN EN 50085

## Classifications

eCl@ss

eCl@ss 10.0.1	27400703
eCl@ss 4.0	27140600
eCl@ss 4.1	27140600
eCl@ss 5.0	27140600

# Cable duct - CD 120X80 - 3240202

## Classifications

### eCl@ss

eCl@ss 5.1	27140600
eCl@ss 6.0	27400700
eCl@ss 7.0	27400703
eCl@ss 8.0	27400703
eCl@ss 9.0	27400703

### ETIM

ETIM 2.0	EC000012
ETIM 3.0	EC000012
ETIM 4.0	EC000012
ETIM 5.0	EC000012
ETIM 6.0	EC000012
ETIM 7.0	EC000012

### UNSPSC

UNSPSC 6.01	30101815
UNSPSC 7.0901	30101815
UNSPSC 11	30101815
UNSPSC 12.01	30101815
UNSPSC 13.2	39131712
UNSPSC 18.0	39131712
UNSPSC 19.0	39131712
UNSPSC 20.0	39131712
UNSPSC 21.0	39131712

## Approvals

### Approvals

#### Approvals

CSA / UL Recognized / VDE Zeichengenehmigung


#### Ex Approvals


### Approval details

CSA		<a href="http://www.csagroup.org/services-industries/product-listing/">http://www.csagroup.org/services-industries/product-listing/</a>	248269
-----	---	---	--------

## Cable duct - CD 120X80 - 3240202

### Approvals

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	FILE E 328576
---------------	---	---	---------------

VDE Zeichengenehmigung		<a href="http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx">http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx</a>	40027969
------------------------	---	---	----------

### Accessories

#### Accessories

##### Cover

Cover profile - CD COVER 120 - 3240290



Cover for cable duct, gray, width: 120 mm, length: 2000 mm

---

##### Filler plug

Fastening clip - RVT-PA 4 - 3240498



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

---

Fastening clip - RVT-PA 6 - 3240499



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

---

##### Riveting tools

## Cable duct - CD 120X80 - 3240202

### Accessories

Tool - UNIFOX-RVT P 4 - 1212478



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

---

Tool - UNIFOX-RVT P 6 - 1212509



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

---

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[3240202](#)