

Cable duct - CD 30X60 WH - 3240621

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Cable duct for installation and mounting in control cabinets, white, comprising upper part and mounting base, width: 30 mm, height: 60 mm, length: 2000 mm

Your advantages

- ✓ Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- ✓ Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- ✓ Predetermined breaking point enables tool-free, burr-free removal of bars
- ✓ The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- ✓ Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- ✓ Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool



Key Commercial Data

| | |
|------------------------|---|
| Packing unit | 24 pc |
| Minimum order quantity | 24 pc |
| GTIN |  4 046356 629379 |
| GTIN | 4046356629379 |

Technical data

Dimensions

| | |
|------------|---------|
| Length (b) | 2000 mm |
| Width (a) | 30 mm |
| Height (c) | 60 mm |

Ambient conditions

| | |
|---------------------------------|-----------------|
| Ambient temperature (operation) | -5 °C ... 60 °C |
|---------------------------------|-----------------|

General

| | |
|--|-----------|
| Color | white |
| Components | Lead-free |
| Flammability rating according to UL 94 | V0 |

Cable duct - CD 30X60 WH - 3240621

Technical data

General

| | |
|-----------------------|----------------------|
| Material | PVC |
| Nominal cross section | 1060 mm ² |

Standards and Regulations


| | |
|--|-----|
| Halogen-free | no |
| Connection in acc. with standard | CSA |
| Flammability rating according to UL 94 | V0 |

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

Drawings

Dimensional drawing

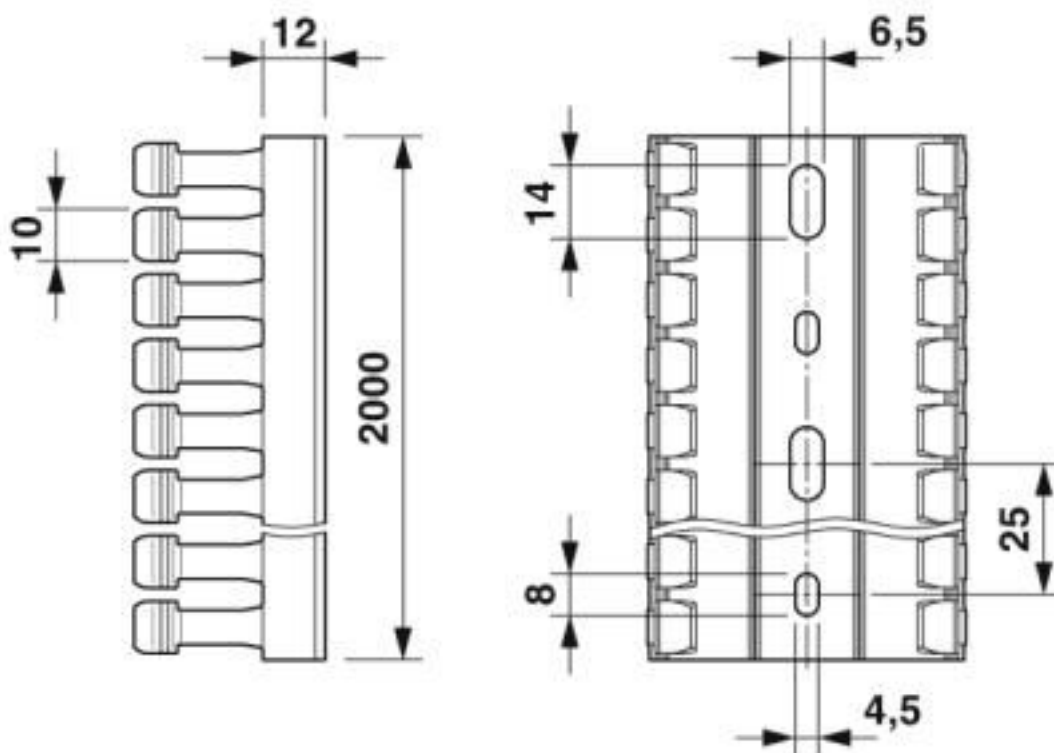

Base perforation according to DIN EN 50085

Classifications

eCl@ss

| | |
|---------------|----------|
| eCl@ss 10.0.1 | 27400703 |
| eCl@ss 4.0 | 27140600 |

Cable duct - CD 30X60 WH - 3240621

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.1 | 27140600 |
| eCl@ss 5.0 | 27140600 |
| eCl@ss 5.1 | 27140600 |
| eCl@ss 6.0 | 27400700 |
| eCl@ss 7.0 | 27400703 |
| eCl@ss 8.0 | 27400703 |
| eCl@ss 9.0 | 27400703 |

ETIM

| | |
|----------|----------|
| ETIM 4.0 | EC000012 |
| ETIM 5.0 | EC000012 |
| ETIM 6.0 | EC000012 |
| ETIM 7.0 | EC000012 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30101815 |
| UNSPSC 7.0901 | 30101815 |
| UNSPSC 11 | 30101815 |
| UNSPSC 12.01 | 30101815 |
| UNSPSC 13.2 | 39131712 |
| UNSPSC 18.0 | 39131712 |
| UNSPSC 19.0 | 39131712 |
| UNSPSC 20.0 | 39131712 |
| UNSPSC 21.0 | 39131712 |

Approvals

Approvals

Approvals

CSA / UL Recognized / VDE Zeichengenehmigung


Ex Approvals


Approval details

| | | | |
|-----|--|---|--------|
| CSA | | http://www.csagroup.org/services-industries/product-listing/ | 248269 |
|-----|--|---|--------|

Cable duct - CD 30X60 WH - 3240621

Approvals

| | | | |
|---------------|---|---|---------------|
| UL Recognized |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | FILE E 328576 |
|---------------|---|---|---------------|

| | | | |
|------------------------|---|---|----------|
| VDE Zeichengenehmigung |  | http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx | 40027969 |
|------------------------|---|---|----------|

Accessories

Accessories

Cover

Cover profile - CD COVER 30 WH - 3240646



Cover for cable duct, white, width: 30 mm, length: 2000 mm

Filler plug

Fastening clip - RVT-PA 4 - 3240498



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

Fastening clip - RVT-PA 6 - 3240499



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

Riveting tools

Cable duct - CD 30X60 WH - 3240621

Accessories

Tool - UNIFOX-RVT P 4 - 1212478



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

Tool - UNIFOX-RVT P 6 - 1212509



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

Wiring duct

Universal wire retaining clip - CD WR - 3240284



Universal wire holding bracket, perforated, for wiring channels

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[3240621](#)