


## Bus system cable - NBC-M12MS/4,0-94D US - 1410128

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Bus system cable, 8-position, PVC, Plug straight M12, cable length: 4 m



### Key Commercial Data

Packing unit	1 pc
Minimum order quantity	50 pc
GTIN	 4 046356 891479
GTIN	4046356891479

### Technical data

#### Dimensions

Length of cable	4 m
-----------------	-----

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)
	-40 °C ... 70 °C (cable, fixed installation)
	-10 °C ... 50 °C (cable, flexible installation)

#### General data

Rated current at 40 °C	2 A
Rated voltage	30 V AC
	30 V DC
Number of positions	8
Overvoltage category	II
Degree of pollution	3
Contact material	CuZn
Contact carrier material	TPU GF
Contact surface material	Ni/Au

#### Characteristics head 1

Head type	Plug straight M12
-----------	-------------------


#### Standards and Regulations

Flammability rating according to UL 94	HB
--	----

## Bus system cable - NBC-M12MS/4,0-94D US - 1410128


### Drawings

Schematic diagram

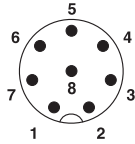

Pin assignment M12 plug, 8-pos., view plug side

Dimensional drawing

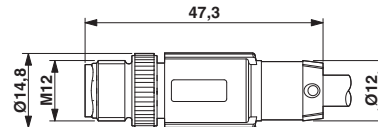

Plug, M12 x 1, straight, shielded

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1410128](#)