

## Sensor/actuator cable - SAC-4P- 6,0-410/MINFS SMC - 1415996


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sensor/actuator cable, 4-position, PVC, yellow, free cable end, on Socket straight 7/8"-16UNF, A-coded, cable length: 6 m, Customer version

RoHS

### Key Commercial Data

Packing unit	25 pc
Minimum order quantity	50 pc
GTIN	 4 055626 057033
GTIN	4055626057033

### Technical data

#### Dimensions

Length of cable	6 m
-----------------	-----

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 80 °C (Plug / socket)
---------------------------------	----------------------------------

#### General

Rated current at 40°C	10 A
Rated voltage	300 V AC
	300 V DC
Number of positions	4
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Status display	No
Protective circuit/component	unwired
Overvoltage category	II
Degree of pollution	2
Insertion/withdrawal cycles	> 500

# Sensor/actuator cable - SAC-4P- 6,0-410/MINFS SMC - 1415996

## Technical data

### Material

Flammability rating according to UL 94	HB
Contact material	CuSn
Contact surface material	Au
Contact carrier material	PUR
Material of grip body	PUR
Material, knurls	Nickel-plated brass

### Standards and Regulations

Flammability rating according to UL 94	HB
--	----

### Cable

 
Conductor cross section	1.5 mm <sup>2</sup>
AWG signal line	16
Conductor structure, voltage supply	65x 0.16 mm
Wire colors	black, white, red, green
External sheath, color	yellow
External cable diameter D	10.67 mm
Outer sheath, material	PVC
Material conductor insulation	PVC
Ambient temperature (operation)	-30 °C ... 105 °C (cable, fixed installation)

### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"


## Drawings

Schematic diagram



Pin assignment, socket, 7/8"-16UNF, 4-pos., view of female side


Dimensional drawing

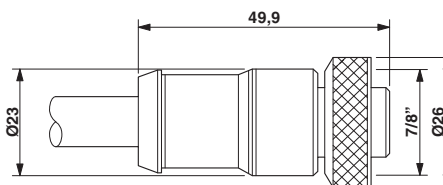

7/8"-16UNF socket, straight

## Sensor/actuator cable - SAC-4P- 6,0-410/MINFS SMC - 1415996

Circuit diagram

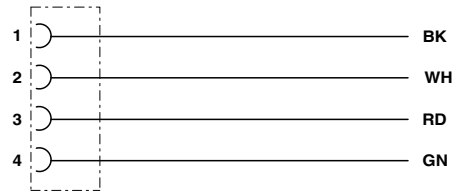

Contact assignment of 7/8" plugs/sockets, cable type 410

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1415996](#)