

Thermomagnetic device circuit breaker - TMC 73D 03A - 1020084

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Thermomagnetic device circuit breaker, number of positions: 3, connection method: Screw, cross section: 1 mm²- 35 mm², AWG: 18 - 2, width: 52.9 mm, mounting type: DIN rail: 35 mm, Color: gray

RoHS

Key Commercial Data

Packing unit	1 pc
Country of origin	China

Technical data

General

Mounting type	DIN rail: 35 mm
Color	gray
Number of positions	3

Electrical data

Operating voltage	277 V AC (277/480Y, 240D)
Rated current I_N	3 A
Rated short-circuit switching capacity I_{cn}	7.5 kA (277/480Y, 240D)

Dimensions

Height	81.4 mm
Width	52.9 mm
Depth	65.7 mm

Ambient conditions

Degree of protection	IP20
Ambient temperature (operation)	-35 °C ... 70 °C

Connection data

Thermomagnetic device circuit breaker - TMC 73D 03A - 1020084

Technical data

Connection data


Conductor cross section solid min.	1 mm ²
Conductor cross section solid max.	35 mm ²
Conductor cross section flexible min.	1 mm ²
Conductor cross section flexible max.	35 mm ²
Conductor cross section AWG min.	18
Conductor cross section AWG max.	2
Connection method	Screw
Tightening torque max	2 Nm

Standards and Regulations


Standards/specifications	UL 1077
	IEC 60947-2

Drawings

Diagram

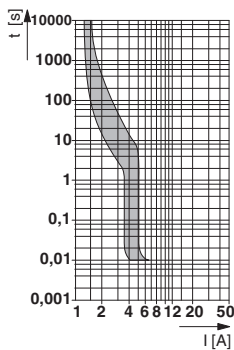

Dimensional drawing

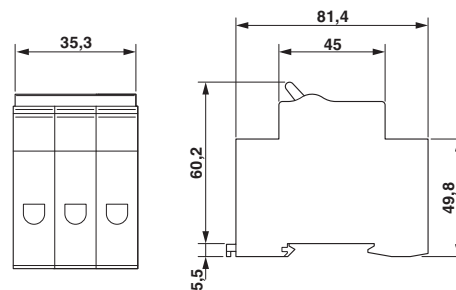

Classifications

eCl@ss

eCl@ss 8.0	27141116
eCl@ss 9.0	27141116

ETIM

ETIM 5.0	EC000899
----------	----------

Approvals

Approvals

Thermomagnetic device circuit breaker - TMC 73D 03A - 1020084




Approvals

Approvals

UL Recognized / cUL Recognized / cULus Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYVV/template/LISEXT/1FRAME/index.htm	FILE E 140459
cUL Recognized		http://database.ul.com/cgi-bin/XYVV/template/LISEXT/1FRAME/index.htm	FILE E 140459
cULus Recognized			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1020084](#)