

371

SR920SW (SR69)
Watch Battery OEM
Swiss Made

Technical Data Sheet


Specifications

Chemical system	Zinc / Monovalent Silver Oxide, Low Drain
Nominal Voltage	1,55 V
Capacity	40 mAh, Discharge over 34,8 k Ω at 20 °C to 1,2 V
Operating Temperature	0 °C – 60 °C
Self Discharge	Less than 5% per year at 20 °C
Weight	~0,61 g

Dimensions


(according to IEC 60086-3)

Diameter	9,50 mm (0,374")
Height	2,05 mm (0,081")

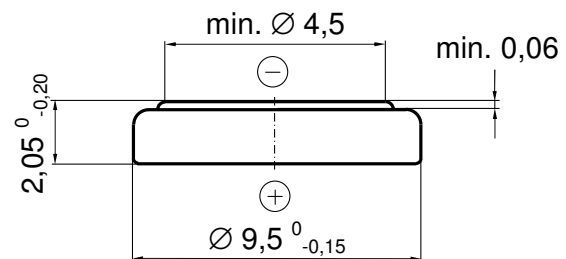

Discharge Curve

Constant Load	34,8 k Ω
Starting Drain	44,8 μ A
Temperature	20 °C

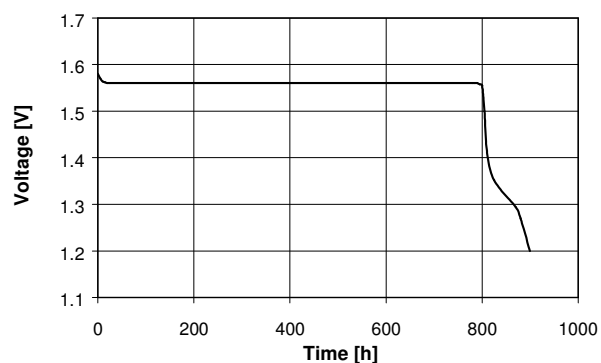

Information and contents in this data sheet are for reference purpose only. They do not constitute any warranty or representation and are subject to change without notice. For most current information and further details, please contact your Renata representative.

Rev. 371.10 2009/07

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Renata:](#)

[371](#)