


8501XTE2

NEMA Control Relay, Type X, pneumatic timer attachment, three minute on delay, 10A resistive at 600 VAC, 1 NO and 1 NC

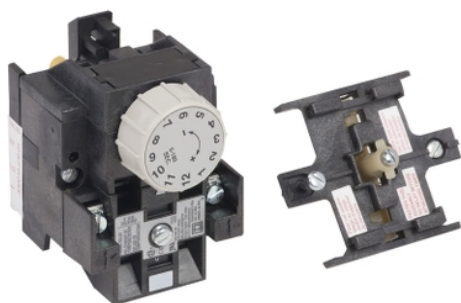

Main

Range of Product	8501X
Relay Type	Control relay
Product or Component Type	Timing relay

Complementary

Contacts Configuration	1 NO/1 NC
Time delay type	On-delay
Time range	5...180 s
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 18...AWG 12 copper
Terminal Tightening Torque	Control circuit 9.03...12.04 lbf.in (1.02...1.36 N.m) screw terminals

Environment

Product Certifications	CE CSA LR60905 class 3211 02 UL recognized E78403 CCN NKCR2
------------------------	---

Ordering and shipping details

Category	21159-8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	785901537366
Nbr. of units in pkg.	1
Package weight(Lbs)	12.48 oz (353.802 g)
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	3.30 in (8.382 cm)
Package 1 width	4.50 in (11.43 cm)
Package 1 Length	6.40 in (16.256 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[8501XTE2](#)