



## Main

Range of product	Harmony XVD Optimum
Product or Component Type	Complete miniature beacon
Beacon or indicator bank unit type	Base unit direct fixing Illuminated unit
Signalling type	Steady
Mounting diameter	1.77 in (45 mm)
Component name	XVDLS
Material	Glass reinforced polyamide base unit Polycarbonate illuminated unit
Light source	Bulb not included, red
Bulb type	Incandescent BA 15d
[Us] rated supply voltage	<= 230 V
Maximum power dissipation in W	5 W

## Complementary

Connections - terminals	Screw clamp terminals, <= 1 x 1.5 mm <sup>2</sup> with cable end
Cable entry	1 entry tapped Pg 7
[Ui] rated insulation voltage	250 V IEC 60947-1
[Uimp] rated impulse withstand voltage	4 kV IEC 60947-1
CAD overall width	1.77 in (45 mm)
CAD overall height	4.09 in (104 mm)
CAD overall depth	1.77 in (45 mm)
Terminals description ISO n°1	(GND)GROUND (COM-1)PW
Product Weight	0.18 lb(US) (0.08 kg)

## Environment

Product Certifications	UL CSA
Standards	EN/IEC 60947-5-1
Protective treatment	TC
Ambient air temperature for operation	-13...158 °F (-25...70 °C)
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Electrical shock protection class	Class II IEC 60536
IP degree of protection	IP40 IEC 60529

## Ordering and shipping details

Category	22611 - XVB-STACKLIGHTS
Discount Schedule	XV
GTIN	3389110110685
Nbr. of units in pkg.	1
Package weight(Lbs)	3.56 oz (101 g)
Returnability	Yes
Country of origin	CZ

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.20 in (5.6 cm)
Package 1 width	2.20 in (5.6 cm)
Package 1 Length	4.41 in (11.2 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	12
Package 2 Weight	3.10 lb(US) (1.405 kg)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

## Contractual warranty


Warranty	18 months
----------	-----------

---

Illuminated Beacon


---

Dimensions

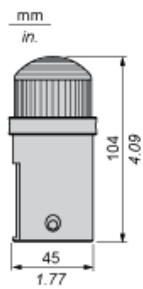

## Illuminated Beacon

### Panel Cut-out for Direct Fixing

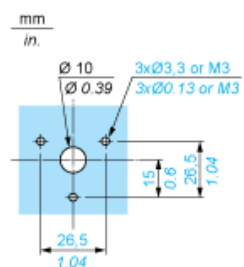

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVDLS34](#)