


Product data sheet

Characteristics

DF2FA125

NFC cartridge fuses, Tesys GS, cylindrical, 22 mm x 58 mm, fuse type aM, 400 VAC, 125 A, without striker

Product availability: Non-Stock - Not normally stocked in distribution facility

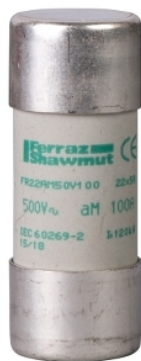

Main

Range of product	TeSys fuse-disconnector
Product or component type	Cartridge fuse
Device short name	DF2
System Voltage	400 V AC
Fuse size	22 x 58 mm
Fuse type	NFC
Quantity per set	Set of 10


Complementary

[In] rated current	125 A 400 V
Fuse curve	AM
Product weight	0.1 lb(US) (0.045 kg)

Ordering and shipping details

Category	22621 - IEC PANEL ACCESSORIES
Discount Schedule	I
GTIN	003389110502879
Nbr. of units in pkg.	10
Package weight(Lbs)	0.01
Returnability	N
Country of origin	TN

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0614 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[DF2FA125](#)