

XVR08B06

Prewired rotating mirror beacon, Harmony
XVR, 84 mm, blue, without buzzer, 24 V AC
DC



Main

Range of Product	Harmony XVR
Product or Component Type	Prewired rotating mirror beacon
Sound signalling	Without
Device short name	XVR
Mounting diameter	3.31 in (84 mm)
IP degree of protection	IP65 IEC 60529 with accessory) IP23 IEC 60529
[Us] rated supply voltage	24 V AC/DC
Light source	High luminosity LED, blue

Complementary

Material	ABS (acrylonitrile butadiene-styrene) body part PC globe
CAD overall width	3.31 in (84 mm)
CAD overall depth	3.31 in (84 mm)
Net Weight	0.66 lb(US) (0.3 kg)
Marking	CE
Product mounting	By 3 M4 screws
Supply voltage limits	19...30 V DC 21.6...26.4 V AC
[Uimp] rated impulse withstand voltage	0.8 kV
Current Consumption	125 mA
Flashing frequency	2.3 Hz
Clamping Connection Capacity	0.83 mm ²
AWG Gauge	AWG 18
Cable length	19.69 in (500 mm)

Environment

Standards	EN 61000-6-2 EN 61000-6-4
Product Certifications	UL
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)
Electrical shock protection class	Class II IEC 61140

Ordering and shipping details

Category	22617-XVC TOWER LIGHTS
Discount Schedule	XV
GTIN	3606480033025
Nbr. of units in pkg.	1
Package weight(Lbs)	13.76 oz (390.0 g)
Returnability	No
Country of origin	ID

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	7.28 in (18.5 cm)
Package 1 width	3.74 in (9.5 cm)
Package 1 Length	3.74 in (9.5 cm)
Unit Type of Package 2	PAL
Number of Units in Package 2	48
Package 2 Weight	41.27 lb(US) (18.72 kg)
Package 2 Height	23.62 in (60 cm)
Package 2 width	31.50 in (80 cm)
Package 2 Length	18.90 in (48 cm)
Unit Type of Package 3	S03
Number of Units in Package 3	6
Package 3 Weight	6.65 lb(US) (3.017 kg)
Package 3 Height	11.81 in (30 cm)
Package 3 width	11.81 in (30 cm)
Package 3 Length	15.75 in (40 cm)

Offer Sustainability


Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Contractual warranty

Warranty	18 months
----------	-----------


Rotating Mirror Beacon

Dimensions

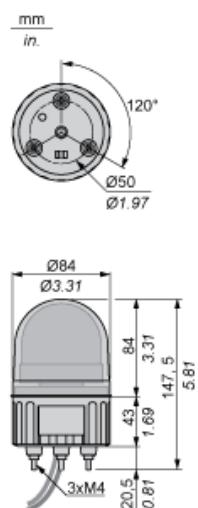

Rotating Mirror Beacon

Panel Cut-out

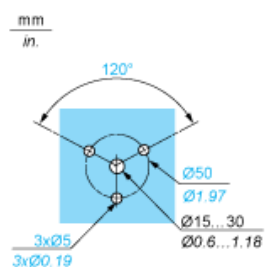

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XVR08B06](#)