



## Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Jumper cable

## Complementary

Jumper cable end 1	M12 male 3 pins straight screw-on
Jumper cable end 2	M8 female 3 pins straight connector with screw-on
Collar material	Metal
Cable composition	3 x 0.25 mm <sup>2</sup>
Cable length	3.28 ft (1 m)
Wire insulation material	PVC
Cable outer diameter	0.18 in (4.6 mm)
[Ue] rated operational voltage	250 V AC 300 V DC
Line Rated Current	3 A
Insulation resistance	>= 1000 MOhm
Maximum resistance across terminals	5000 mOhm
Net Weight	0.11 lb(US) (0.05 kg)

## Environment

IP degree of protection	IP65 IP67
Product certifications	CULus
Ambient air temperature for operation	-13...176 °F (-25...80 °C) static
Ambient air temperature for storage	-13...176 °F (-25...80 °C)

## Ordering and shipping details

Category	22483 - MACHINE CABLES
Discount Schedule	DS3
GTIN	03389119621670
Nbr. of units in pkg.	10
Package weight(Lbs)	10 lb(US) (4.54 kg)
Returnability	No


## Packing Units

Package 1 Height	0.200 dm
Package 1 width	1.200 dm
Package 1 Length	1.200 dm

## Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>

Dimensions

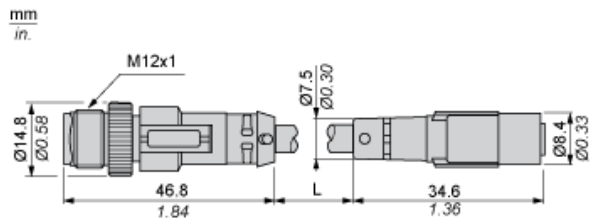


L : Length of cable

---

## Connections and Schemes

---

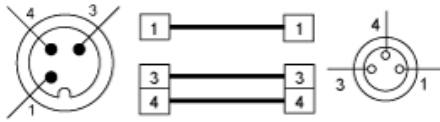

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XZCRV1501040G1](#)