


Product availability: Stock - Normally stocked in distribution facility

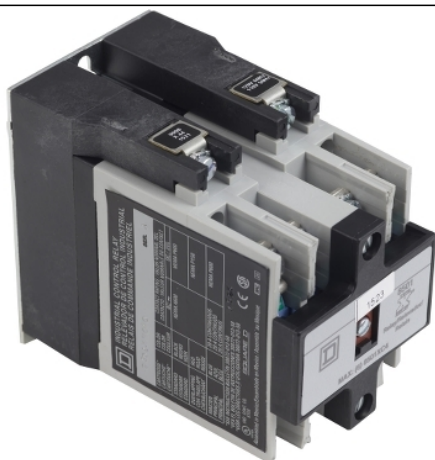


### Main

Range	8501X
Relay Type	Master
Product	Relay
Current Rating	20 A AC
Contact Configuration	4 NO 4 master contact cartridges
Number of Poles	4P
Coil Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Voltage Rating	600 V AC
Mounting Type	Panel
Operating Temperature	-40...160 °F
Electrical Connection	Screw clamp terminals
Certifications	CE CSA UL listed
Operating Time	15 ms pick-up 16 ms drop-out

### Ordering and shipping details

Category	21158 - 8501 XO (AC)
Discount Schedule	CP2
GTIN	00785901743446
Nbr. of units in pkg.	1
Package weight(Lbs)	2.1000000000000001
Returnability	Y
Country of origin	MX

### Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 1332 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Available
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

### Contractual warranty

Warranty period	18 months
-----------------	-----------

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Schneider Electric:

[8501XMO40V02](#)