

# Product data sheet

## Characteristics

# XZCPV0766L10

pre-wired connectors XZ - elbowed female - M8  
- 3 pins - cable PVC 10m

Product availability: Non-Stock - Not normally stocked in distribution facility



### Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	General purpose

### Complementary

Electrical connection	M8, 3 pins elbowed female connector
Cable connector fixing	Screw-on
Collar material	Metal
Status LED	2 PNP LEDs
Cable length	32.81 ft (10 m)
Cable outer diameter	0.18 in (4.6 mm)
Cable composition	3 x 0.25 mm <sup>2</sup>
Wire insulation material	PVC
System Voltage	30 V AC 36 V DC
Line Rated Current	3 A
Contact resistance	5000 µOhm
Insulating resistance	1 GΩ
Product weight	0.79 lb(US) (0.36 kg)


### Environment

IP degree of protection	IP65 IP67
Product certifications	cULus
Ambient air temperature for operation	-13...176 °F (-25...80 °C) (static)
Ambient air temperature for storage	-13...176 °F (-25...80 °C)

### Ordering and shipping details

Category	22483 - MACHINE CABLES
Discount Schedule	DS3
GTIN	003389119073462
Nbr. of units in pkg.	1
Package weight(Lbs)	0.7900000000000004
Returnability	N
Country of origin	PL


## Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1201 - Schneider Electric declaration of conformity  <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
----- Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

## Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

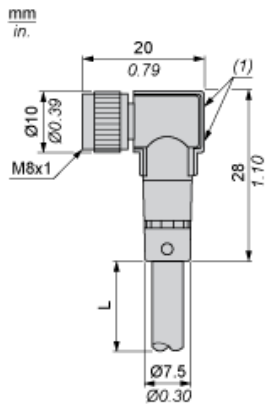

L : Length of cable


(1) 2 LEDs limited to 10...30 VDC max.

---

## Connections and Schemes

---

### Connector

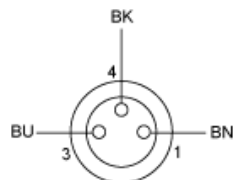


BU : Blue  
BN : Brown  
BK : Black

---

## Connections and Schemes

---

### LED Connection

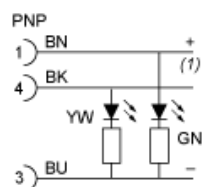

BN : Brown  
BK : Black  
BU : Blue  
GN : Green  
YW : Yellow  
(1) Signal

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XZCPV0766L10](#)