


Product availability: Non-Stock - Not normally stocked in distribution facility

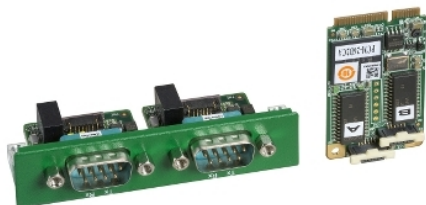

Main

Range of product	Magelis iPC
Product or component type	CANopen/CANBus interface
Accessory / separate part category	Connection accessory

Complementary

Accessory / separate part destination	Magelis iPC with Mini PCIe slot
Integrated connection type	Mini PCIe full-size with 2 female SUB-D 9, transmission rate: 1 Mbit/s, transmission frequency: 16 MHz 2 m cable
Input current	400 mA at 5 V DC
Range compatibility	Magelis iPC
Width	2.99 in (76 mm)
Height	3.19 in (81 mm)
Depth	1.5 in (38.2 mm)

Environment

Ambient air temperature for operation	-40...185 °F (-40...85 °C)
Ambient air temperature for storage	-4...140 °F (-20...60 °C)
Relative humidity	5...95 % non-condensing

Ordering and shipping details

Category	22574 - MAGELIS BOX PC AND PANEL PC
Discount Schedule	MC2
GTIN	00785901705895
Nbr. of units in pkg.	1
Package weight(Lbs)	0.2999999999999999
Returnability	N
Country of origin	TW

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[HMIYMINCAN1](#)