


SERPAC WM021i

ELECTRONIC ENCLOSURES

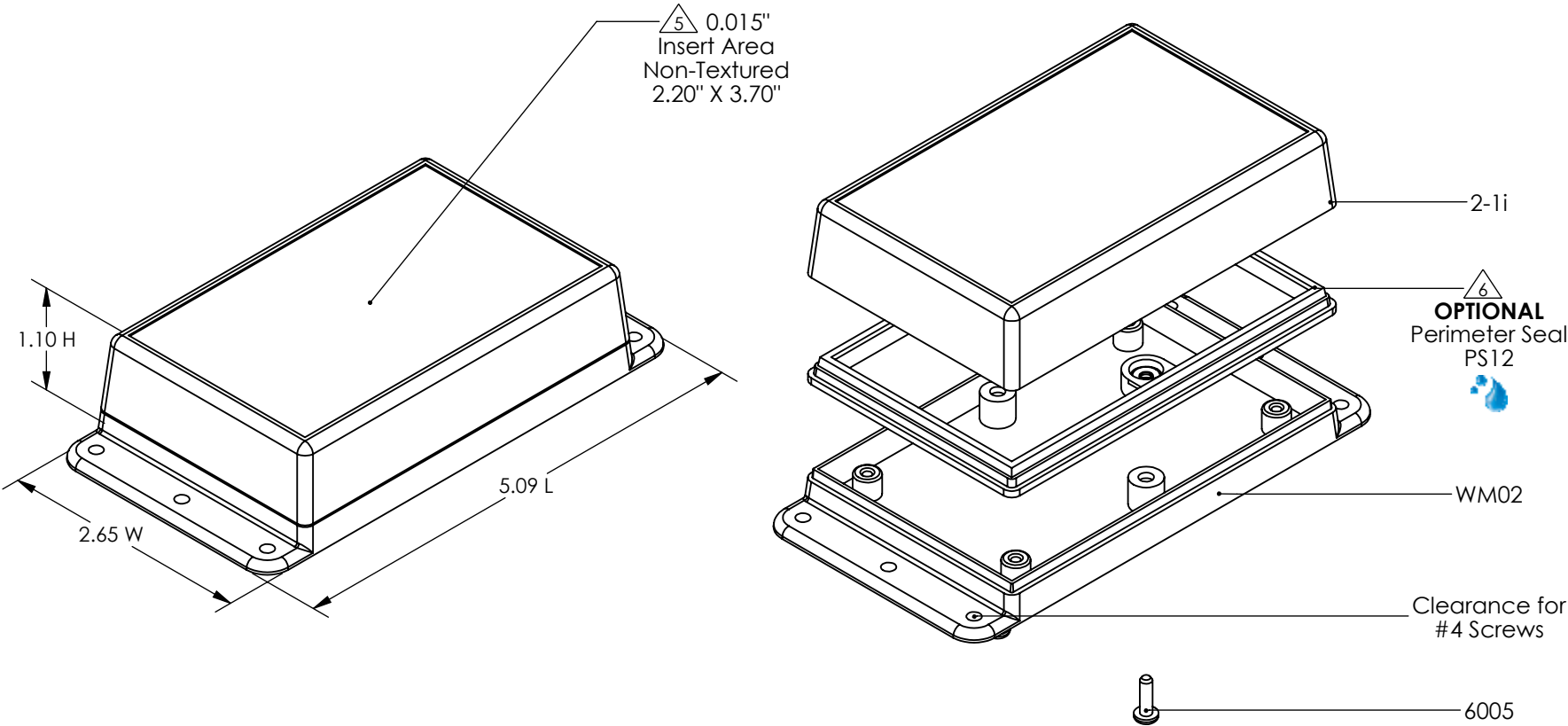

PART NO.	DESCRIPTION (Included)	PART NO.	DESCRIPTION
2-1i	Top	60	Standoff Hole
WM02	Wall Mounted Bottom	61	Standoff Post
6005	#4X3/8" Self-Tapping Screw (2)	PS12	Waterproof Perimeter Seal

Notes: Enclosure weight .15 lb / 66 g

1) Enclosure meets or exceeds IP40 and NEMA 1

2) Circuit Board drawings see sheet 3.





3) All components are RoHS Compliant.

4) Material: Top and Bottom ABS.

5) Customizable molding areas. $\triangle 5$

6) When used with PS12 the enclosure meets or exceeds IP 67 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (.02 lb / 7g) $\triangle 6$


SERPAC WM021i
ELECTRONIC ENCLOSURES

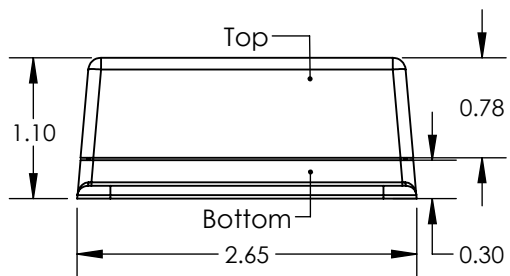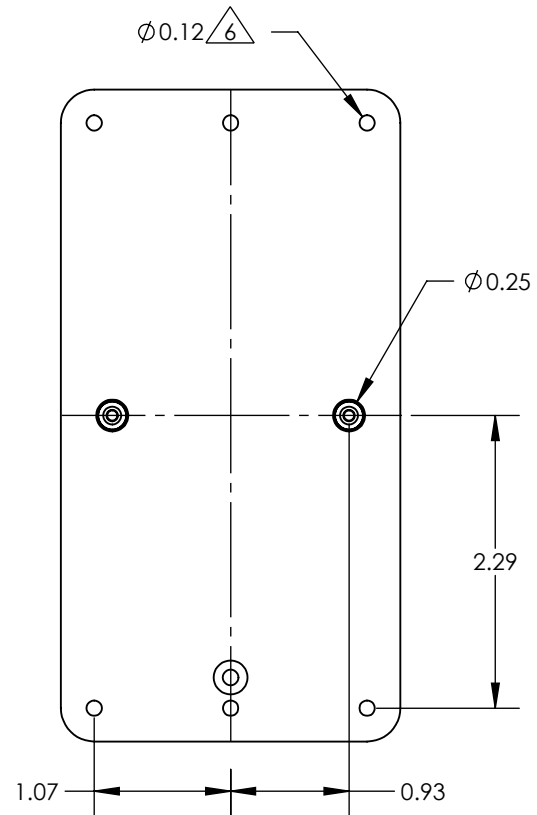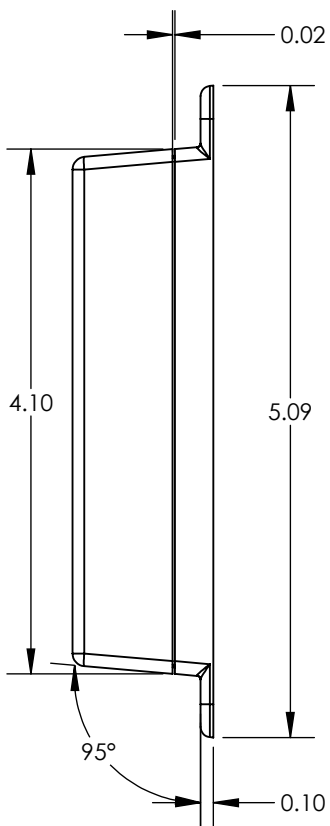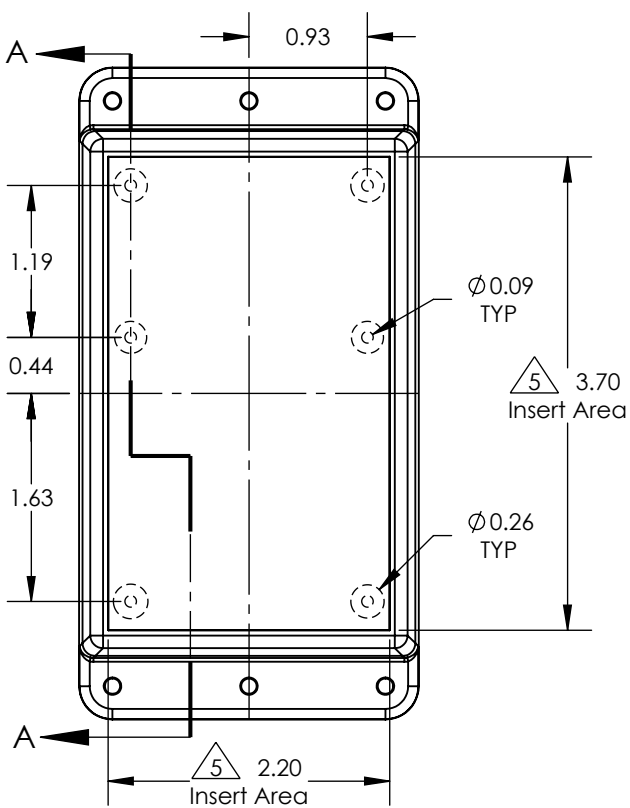


Notes:

Enclosure weight .15 lb / 66 g

- 1) Enclosure meets or exceeds IP40 and NEMA 1
- 2) Circuit Board drawings see sheet 3.
- 3) All components are RoHS Compliant.
- 4) Material: Top and Bottom ABS.
- 5) Customizable molding areas. 
- 6) Accepts #4 self tapping screw. 
- 7) When used with PS12 the enclosure meets or exceeds IP40 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (0.000156 inch)

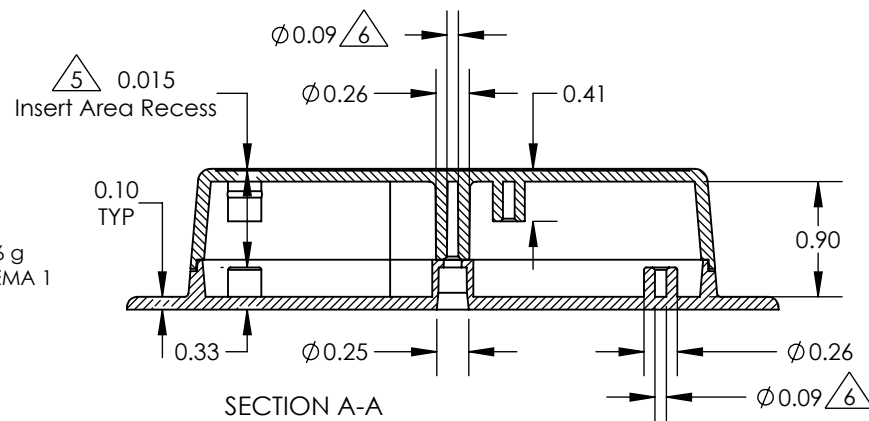

Top & Bottom Option

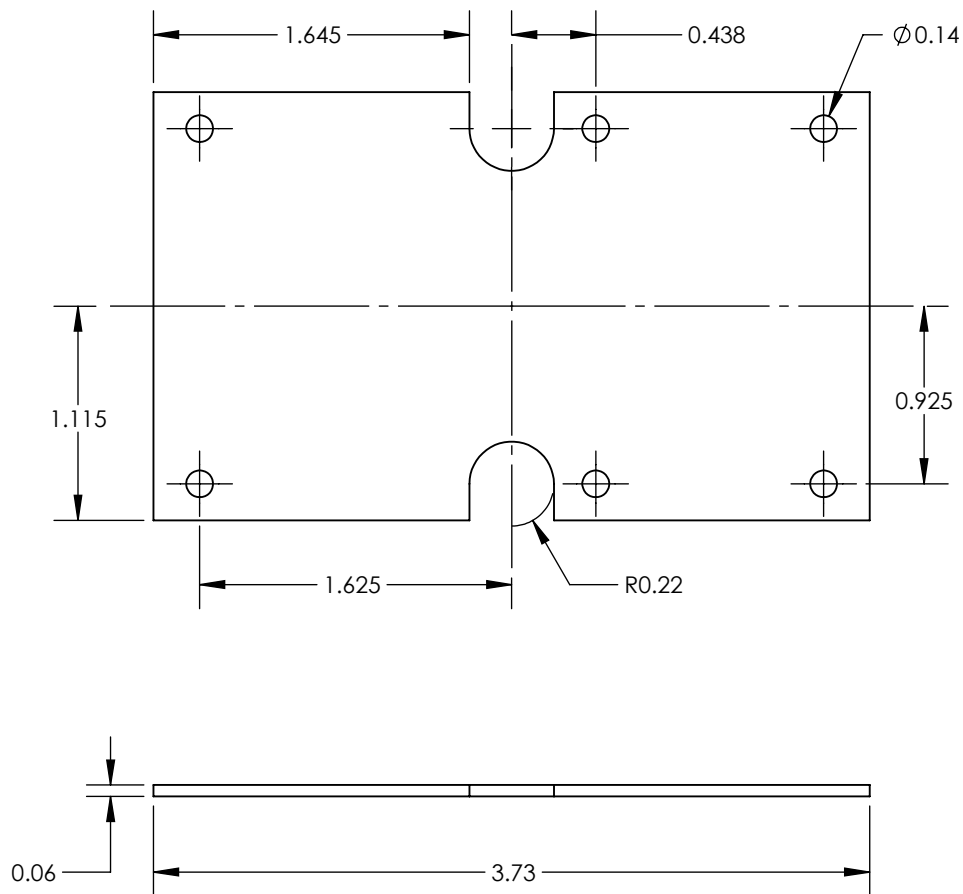

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SERPAC:](#)

[WM021IAL](#) [WM021IBK](#) [WM021IGY](#) [WM021I,AL](#) [WM021I,BK](#) [WM021I,GY](#)